

UHGMXMXAD

Base Product



Ultra Low Loss (ULL) Singlemode MPO12 (Pinned) to MPO12 (Pinned) Armored Pre-terminated Trunk Cable, 12-Fiber, Plenum

OBSOLETE

This product was discontinued on: April 30, 2024

Replaced By:

UHGMXMXCD

Singlemode MPO12 APC (pinned) to MPO12 APC (pinned) Fiber Trunk Cable Assembly, 12-Fiber, Armored Indoor Plenum

Product Classification

Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Connector A, quantity	1
Color, boot A	Black
Color, connector A	Green
Connector B, quantity	1
Color, boot B	Black
Color, connector B	Green
Construction Type	Armored Stranded
Furcation Color	Yellow
Interface, Connector A	MPO-12/APC Male
Interface Feature, connector A	Pinned


UHGMXXMAD

Interface, Connector B	MPO-12/APC Male
Interface Feature, connector B	Pinned
Jacket Color	Yellow
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	12
Total Fibers, quantity	12

Dimensions

Breakout Length	33 in
Cable Assembly Length Range (m)	3 – 999
Cable Assembly Length Range (ft)	10 – 999

Ordering Tree

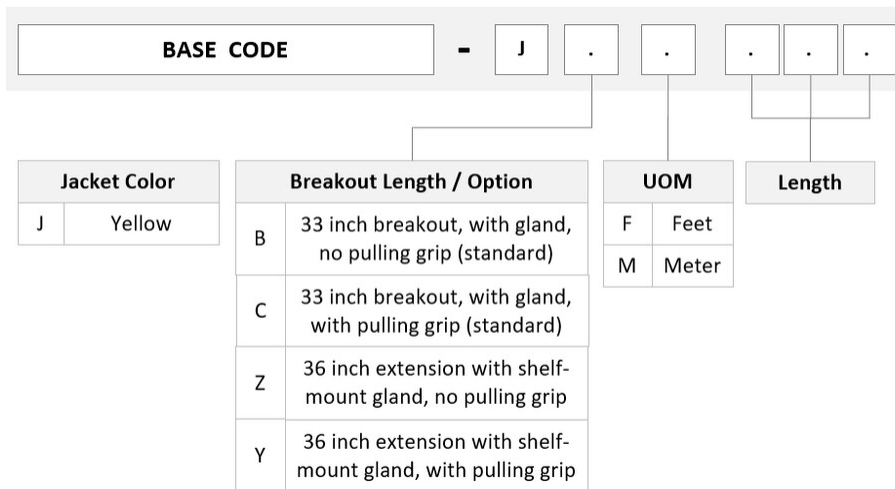

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A2, TeraSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Indoor Plenum

Regulatory Compliance/Certifications

UHGMXXMXAD

Agency

ANATEL

**Classification**

Compliant

Included Products

860638317 – MPO12, ULTRA LOW LOSS, MALE, Singlemode, GREEN, 3mm