

# UKGQXUCTR

Base Product



Singlemode MPO8 APC (pinned) to Unconnectorized Fiber Trunk Cable Assembly, 16-Fiber, Armored Indoor Dual Rated (OFNR/LSZH)

## Product Classification

### Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

### Portfolio

CommScope®

### Product Type

Fiber trunk cable assembly

### Product Brand

Propel | SYSTIMAX ULL

### Ordering Note

For additional jacket colors, please contact a CommScope Sales Representative | For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

## General Specifications

### Connector A, quantity

2

### Color, boot A

Gray

### Color, connector A

Green

### Connector B, quantity

0

### Construction Type

Armored | Stranded

### Furcation Color

Yellow

### Interface, Connector A

MPO-08/APC Male

### Interface, Connector B

Unterminated

### Jacket Color

Yellow

### Polarity

Method B Enhanced (ULL)

### Fibers per Subunit, quantity

8

### Total Fibers, quantity

16

## Dimensions

### Breakout Length

22 in

### Cable Assembly Length Range (m)


3 – 305

### Cable Assembly Length Range (ft)

10 – 999

# UKGQXUCTR

## Ordering Tree

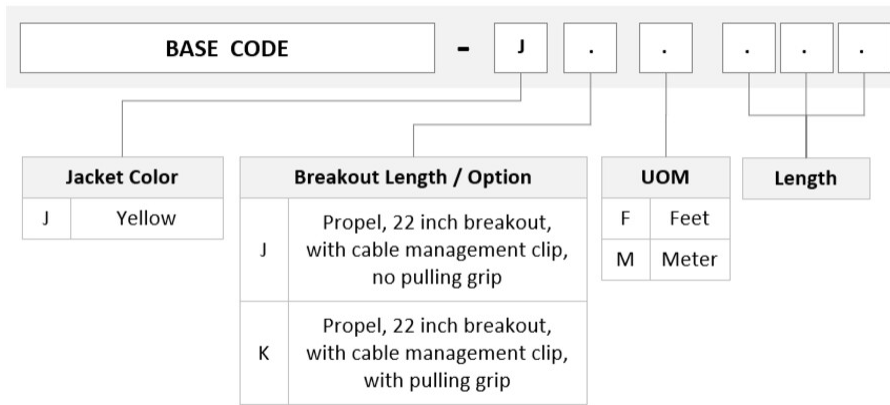

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0° | 4.40 lb @ 90°

## Optical Specifications

**Fiber Mode** Singlemode

**Fiber Type** G.657.A2, TeraSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**EN50575 CPR Cable EuroClass Fire Performance** Dca

**Environmental Space** Dual Rated LSZH/Riser | Indoor

## Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

# UKGQXUCTR

---



## Included Products

- 760255997  
N-016-MZ-8G1-F08YL/20T/B2
  - 860659022
- Fiber indoor cable, Riser/LSZH rated MPO Trunk, interlocking aluminum armored, Singlemode G.657.A2/B2, 16 fiber, Feet jacket marking, Yellow jacket color, B2ca flame rating
  - MPO-08, ULTRA LOW LOSS, MALE, Singlemode, GREEN, 2mm