

# AJG2P2PBF

## Base Product



Singlemode MPO24 (Non-pinned) to MPO24 (Non-pinned), Fiber Trunk Cable Assembly, 24-Fiber, Low Smoke Zero Halogen (LSZH), Method A

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   Europe   Latin America   Middle East /Africa   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber trunk cable assembly
<b>Product Brand</b>	SYSTIMAX ULL

## General Specifications


<b>Color, boot A</b>	Red
<b>Color, connector A</b>	Green
<b>Color, boot B</b>	Red
<b>Color, connector B</b>	Green
<b>Construction Type</b>	Stranded
<b>Furcation Color</b>	Yellow
<b>Interface, Connector A</b>	MPO-24/APC Female
<b>Interface, Connector B</b>	MPO-24/APC Female
<b>Jacket Color</b>	Yellow
<b>Polarity</b>	Method A
<b>Fibers per Subunit, quantity</b>	24
<b>Total Fibers, quantity</b>	24

## Dimensions

<b>Cable Assembly Length Range (m)</b>	3 – 999
<b>Cable Assembly Length Range (ft)</b>	10 – 999

## Ordering Tree

# AJG2P2PBF

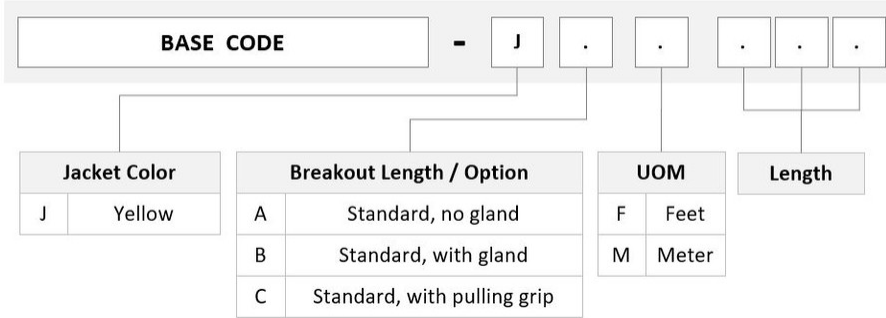

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0° | 4.40 lb @ 90°

## Optical Specifications

**Fiber Mode** Singlemode

**Fiber Type** G.657.A2/B2

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Dual Rated LSZH/Riser

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



## Included Products

- 760238981 N-024-MP-8G-F24YL/D - Low Smoke Zero Halogen Riser MPO Trunk Cable, 24 fiber
- 760248637 N-024-MP-8G1-F24YL/30T/B2 - Fiber indoor cable, Low Smoke Zero Halogen Riser MPO Trunk, 24 fiber with 24-fiber, 3.0 mm subunits, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color, B2ca flame rating
- 860662281 - MPO24,FEMALE,SM, GREEN,3.0MM