



OFDC C12 Fiber Optic Series with Rural Taps, Gel Cable sealing, 4 drop taps @ 9dB each, No mounting kit

- Advanced gel sealing technology ensures fast and easy field handling without a need for special tools
- Individual access to drop cable connection area and seperate zones for looped cable storage for most cable types
- Compact and modular design suited for wraparound drop cable installation, enabling faster deployments
- Allows easy pass-through cabling and integration of optical components, even at later deployment stages

Product Classification

Regional Availability	Asia   EMEA   Latin America   North America
Product Type	Single-ended, rectangular fiber closure
Product Series	OFDC

General Specifications


Cable Capacity, Drop	12 Flat 8.0 x 4.5 mm (0.30 x 0.17 in)   12 Round 1.5–5.5 mm (0.06–0.21 in)   24 Round 2.0–5.5 mm (0.07–0.21 in)
Cable Capacity, Feeder	2 Round 5.5–17.5 mm (0.21–0.68 in)
Cable Ports Quantity, total	4 round ports + 12 multi-out ports (24 cables)
Cable Sealing Type	Compressed gel
Closure Sealing Type	Hinged with latch
Closure Style	Single-ended
Color	Black
Mounting	Manhole   Pedestal   Strand   Wall
Port Type	SC/APC
Port, quantity	12
Splice Tray Included, quantity	2
Splice Tray Type Included	48-way, heat shrink
Splicing Capacity, maximum	96
Splicing Type, Supported	Single fusion
Splitter Type	No splitter
Splitter, quantity	0

# 760258558 | OFDC-C12-S2/40-4T09-N-HD

## Dimensions

Height	118 mm   4.646 in
Width	214 mm   8.425 in
Length	370 mm   14.567 in
Splice Protector Length, maximum	45 mm   1.772 in

## Ordering Tree

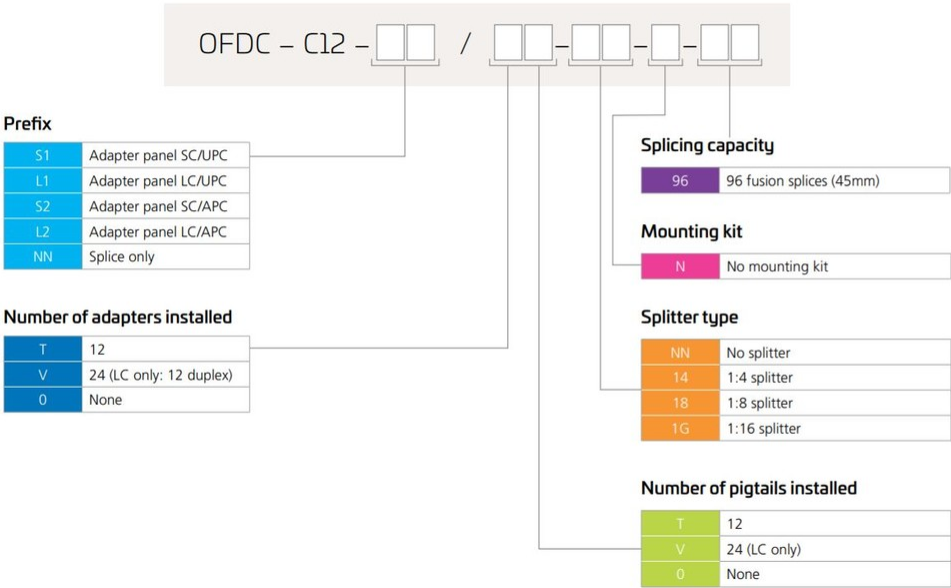

## Material Specifications

Material Type	Rugged polymer
---------------	----------------

## Environmental Specifications

Installation temperature	-5 °C to +45 °C (+23 °F to +113 °F)
Storage Temperature	-30 °C to +60 °C (-22 °F to +140 °F)
Relative Humidity	93%, non-condensing
Environmental Space	Above ground   Below ground
Qualification Standards	IEC 60529, IP68 + 2 m waterhead
UV Resistance	UV stabilized

Packaging and Weights

Included	Fiber pigtail assemblies (12)   SC/APC adapters (12)
Packaging quantity	1
Packaging Type	Box   Carton
Weight, net	2.5 kg   5.512 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

