


# CX3750001 | 200T040P3750JCASS COEX

ConQuest® Cable in Conduit, 2 in, SCH 40, terracotta (P3® 750 JCASS)

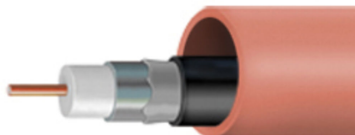

## Product Classification

Product Type	Coaxial cable-in-conduit
Product Brand	ConQuest®
Product Series	750 Series

## General Specifications

Cable Type	750 series
Cable-In-Conduit Type	P3® in duct
Color	Terracotta
Conduit Type	Non-toneable
Wall Type	Smooth

## Dimensions

Length	762 m   2500 ft
Wall Thickness Designation	SCH 40
Nominal Size	2 in

## Packaging and Weights

Weight, net	1,005.999 kg/km   676 lb/kft
-------------	------------------------------

## Included Products

5304203 P3® 750 JCASS	–	75 Ohm P3® Trunk and Distribution Cable, black PE jacket, flooded for underground
CX3799999 200T040 EMPTY DUCT COEX	–	ConQuest® Empty Conduit, 2 in, SCH 40, terracotta