


CX3750003 | 200T040P3875JCASS COEX

ConQuest® Cable in Conduit, 2 in, SCH 40, terracotta (P3® 875 JCASS)

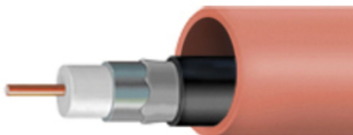

Product Classification

Product Type	Coaxial cable-in-conduit
Product Brand	ConQuest®
Product Series	875 Series

General Specifications

Cable Type	875 series
Cable-In-Conduit Type	P3® in duct
Color	Terracotta
Conduit Type	Non-toneable
Wall Type	Smooth

Dimensions

Length	762 m 2500 ft
Wall Thickness Designation	SCH 40
Nominal Size	2 in

Packaging and Weights

Weight, net	1,092.312 kg/km 734 lb/kft
-------------	------------------------------

Included Products

5309103 P3® 875 JCASS	-	75 Ohm P3® Trunk and Distribution Cable, black PE jacket, flooded for underground
5309193 P3® 875 JCASS	-	75 Ohm P3® Trunk and Distribution Cable, black PE jacket, flooded for underground
CX3799999 200T040 EMPTY DUCT COEX	-	ConQuest® Empty Conduit, 2 in, SCH 40, terracotta

