


760237010 | FIST-GPSTF-12-AAL2-2

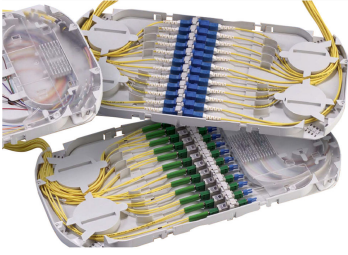

FIST GPST Fiber Patch Tray, 24 ports, LC/APC, singlemode, 15 in, gray, left/right patch cord routing

Product Classification

Regional Availability	EMEA
Product Type	Fiber patch tray
Product Brand	FIST®
Product Series	FIST-GPST

General Specifications

Functionality	Patching
Color	Gray
Interface, front	LC/APC
Patch Cord Entry Location	Front, left side Front, right side
Patching Capacity, maximum	24
Splicing Capacity, maximum	0
Total Ports, quantity	24

Dimensions

Height	16 mm 0.63 in
Width	315 mm 12.402 in
Depth	190 mm 7.48 in

Optical Specifications

Fiber Mode	Singlemode
-------------------	------------

Environmental Specifications

Operating Temperature	-5 °C to +45 °C (+23 °F to +113 °F)
------------------------------	-------------------------------------

760237010 | FIST-GPSTF-12-AAL2-2

Storage Temperature -30 °C to +60 °C (-22 °F to +140 °F)

Relative Humidity Up to 93%, non-condensing

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ROHS	Compliant
UK-ROHS	Compliant

