


# CK6448-000 | FOSC-OPGW-A4NT-0-NNC

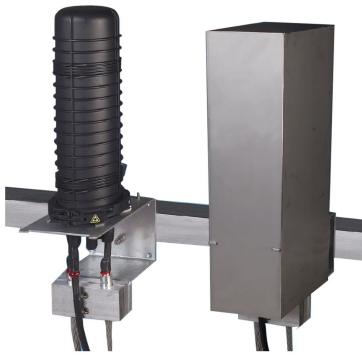

FOSC® OPGW A Fiber Optic Splice Closure, Heat Shrink Cable sealing, butt type, no pre-installed trays

## Product Classification

<b>Regional Availability</b>	Asia   EMEA   Latin America   North America
<b>Product Type</b>	Single-ended, round fiber closure
<b>Product Brand</b>	FOSC®
<b>Product Series</b>	FOSC OPGW

## General Specifications


<b>Cable Entry Drop Port Style</b>	Round
<b>Cable Entry Main Port Style</b>	Round
<b>Cable Ports Quantity, total</b>	1 oval port (2 cables) + 4 round ports
<b>Cable Sealing Type</b>	Heat shrink
<b>Closure Sealing Type</b>	Dome-to-base clamp with O-ring
<b>Closure Style</b>	Single-ended
<b>Color</b>	Black
<b>Ground Feed-through</b>	None
<b>Mounting</b>	Pole   Strand   Wall
<b>Network Area Type</b>	Feeder
<b>Splice Tray Included, quantity</b>	0
<b>Splice Tray Type Included</b>	No trays
<b>Splicing Capacity, Single Fusion, maximum</b>	48
<b>Splicing Capacity, Single Splice, 12 fibers, maximum</b>	48
<b>Splicing Capacity, Single Splice, 6 fibers, maximum</b>	24
<b>Splicing Type, Supported</b>	Mass fusion   Single fusion

## Dimensions

# CK6448-000 | FOSC-OPGW-A4NT-0-NNC

<b>Height</b>	240 mm   9.449 in
<b>Width</b>	202 mm   7.953 in
<b>Length</b>	730 mm   28.74 in
<b>Main Cable Diameter, maximum</b>	19 mm   0.748 in

## Ordering Tree

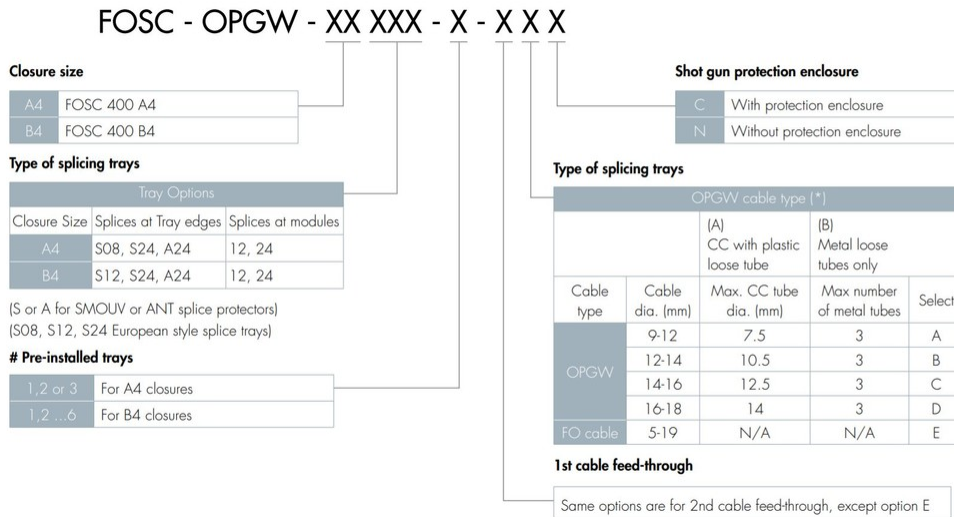

## Material Specifications

**Material Type** Impact-resistant polymer

## Environmental Specifications

**Environmental Space** Above ground

**Qualification Standards** IEC 61300, 6 m waterhead

## Packaging and Weights

**Packaging quantity** 1

**Packaging Type** Box | Carton

**Weight, net** 18 kg | 39.683 lb

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

# CK6448-000 | FOSC-OPGW-A4NT-0-NNC

---

REACH-SVHC

Compliant as per SVHC revision on [www.commscope.com/ProductCompliance](http://www.commscope.com/ProductCompliance)

ROHS

Compliant

UK-ROHS

Compliant

