


# CK6628-000 | FIST-GPST-12-ANLC-2

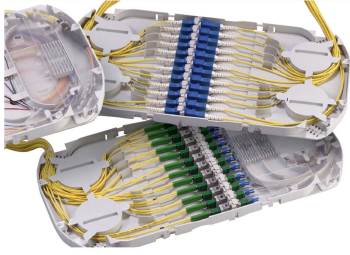

FIST GPST Fiber Termination/Splice Tray, 12 ports, FC/UPC, singlemode, ANT splice chip, 19 in, gray, right patch cord routing

## OBSOLETE

This product was discontinued on: **March 1, 2018**

## Product Classification

<b>Regional Availability</b>	EMEA
<b>Product Type</b>	Fiber patch/splice tray
<b>Product Brand</b>	FIST®
<b>Product Series</b>	FIST-GPST

## General Specifications

<b>Functionality</b>	Patching   Splicing
<b>Color</b>	Gray
<b>Interface, front</b>	FC/UPC
<b>Patch Cord Entry Location</b>	Front, right side
<b>Splicing Type</b>	ANT, single fiber fusion
<b>Total Ports, quantity</b>	24

## Dimensions

<b>Height</b>	18 mm   0.709 in
<b>Width</b>	355 mm   13.976 in
<b>Depth</b>	190 mm   7.48 in

## Optical Specifications

<b>Fiber Mode</b>	Singlemode
-------------------	------------

# CK6628-000 | FIST-GPST-12-ANLC-2

---

## Environmental Specifications

<b>Operating Temperature</b>	-5 °C to +45 °C (+23 °F to +113 °F)
<b>Storage Temperature</b>	-30 °C to +60 °C (-22 °F to +140 °F)
<b>Relative Humidity</b>	Up to 93%, non-condensing

## Packaging and Weights

<b>Packaging quantity</b>	1
---------------------------	---

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant

