


CW9532-000 | IFDB-PNP-S2

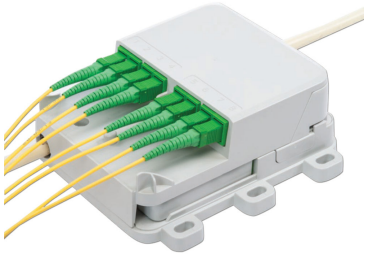

IFDB Fiber Optic Wall Box, plug & play, with 1 SC/APC adapter port and pigtail

- Allows splicing those fibers from an indoor riser cable to the individual drops
- Allows fibers from certain riser cables to be broken out without interrupting the strength member
- Separate storage of un-connected fibers from spliced drop fibers
- Compatible with mechanical, SMOUV and ANT splice protectors
- In-line and butt configuration possible for main riser cable

Product Classification

Regional Availability	EMEA
Product Type	Fiber wall box
Product Series	IFDB

General Specifications

Functionality	Patching Splitting
Adapters, quantity	4
Color	Light gray
Front Cover Type	Screw-on
Interface	SC/APC
Mounting	Floor Wall

Dimensions

Height	125 mm 4.921 in
Width	125 mm 4.921 in
Depth	55 mm 2.165 in

Material Specifications

Material Type	Thermoplastic
----------------------	---------------

Optical Specifications

Fiber Mode	Singlemode
-------------------	------------

Environmental Specifications

CW9532-000 | IFDB-PNP-S2

Environmental Space	Indoor
Flammability Rating	UL 94 V-0
Qualification Standards	IEC 60529, IP30

Packaging and Weights

Included	Fiber pigtail assemblies
Packaging quantity	12
Packaging Type	Bag Carton

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

