

# EF7078-003 | EFDT-12HMFOC-S4-60MIO-TE



RapidFiber® EFDT Wall Mounting Fiber Box, outdoor, 12 SC/APC, HMFOC at far end, 60 m

- Designed to provide a quick and simple solution for installing fiber in small and medium sized MDU's
- Incorporates a unique fiber cable spooling system that stores up fiber cable within the enclosure
- Removes the need for field termination and extensive site survey inspections
- Weatherproof housing suitable for external environmental conditions

## OBSOLETE

This product was discontinued on: February 28, 2019

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   EMEA   Latin America   North America
<b>Product Type</b>	Fiber wall box
<b>Product Brand</b>	RapidFiber®
<b>Product Series</b>	EFDT

## General Specifications

<b>Functionality</b>	Patching
<b>Access</b>	Front
<b>Cable Color</b>	White
<b>Cable Type</b>	Microcable - Loose Tube
<b>Enclosure Color</b>	Gray
<b>Front Cover Type</b>	Hinged with lock
<b>Interface</b>	SC/APC
<b>Interface, stub</b>	HMFOC
<b>Mounting</b>	Wall
<b>Port, quantity</b>	12


## Dimensions

<b>Height</b>	264.16 mm   10.4 in
<b>Width</b>	179.07 mm   7.05 in

# EF7078-003 | EFDT-12HMFOC-S4-60MIO-TE

<b>Depth</b>	71.12 mm   2.8 in
<b>Cable Length</b>	60 m   196.85 ft

## Ordering Tree

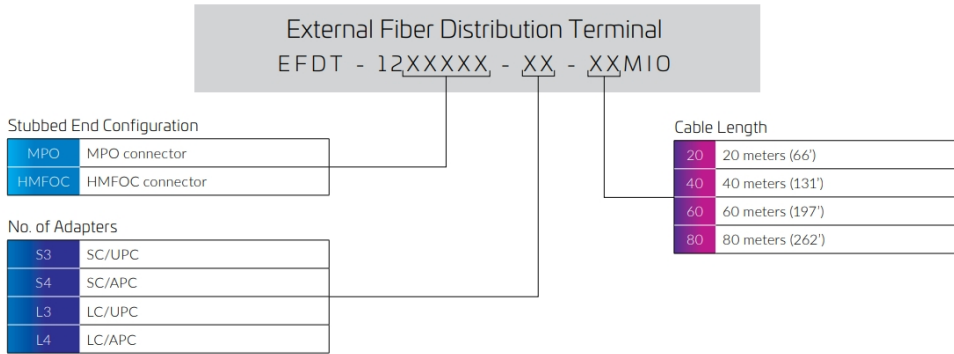

## Material Specifications

<b>Enclosure Material Type</b>	LSZH thermoplastic
--------------------------------	--------------------

## Optical Specifications

<b>Fiber Mode</b>	Singlemode
<b>Fiber Type</b>	G.657.A2
<b>Insertion Loss, Terminal Connector, typical</b>	0.4 dB
<b>Return Loss, Connector, minimum</b>	55 dB

## Environmental Specifications

<b>Environmental Space</b>	Outdoor
----------------------------	---------

## Packaging and Weights

<b>Packaging quantity</b>	1
<b>Packaging Type</b>	Box   Carton

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="https://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant

UK-ROHS

Compliant

