

EF7078-004 | EFDT-12HMFOC-S4-80MIO-TE



RapidFiber® EFDT Wall Mounting Fiber Box, outdoor, 12 SC/APC, HMFOC at far end, 80 m

- Designed to provide a quick and simple solution for installing fiber in small and medium sized MDU's
- Incorporates a unique fiber cable spooling system that stores up fiber cable within the enclosure
- Removes the need for field termination and extensive site survey inspections
- Weatherproof housing suitable for external environmental conditions

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Product Type	Fiber wall box
Product Brand	RapidFiber®
Product Series	EFDT

General Specifications


Functionality	Patching
Access	Front
Cable Color	White
Cable Type	Microcable - Loose Tube
Enclosure Color	Gray
Front Cover Type	Hinged with lock
Interface	SC/APC
Interface, stub	HMFOC
Mounting	Wall
Port, quantity	12

Dimensions

Height	264.16 mm 10.4 in
Width	179.07 mm 7.05 in
Depth	71.12 mm 2.8 in
Cable Length	80 m 262.467 ft

EF7078-004 | EFDT-12HMFOC-S4-80MIO-TE

Ordering Tree

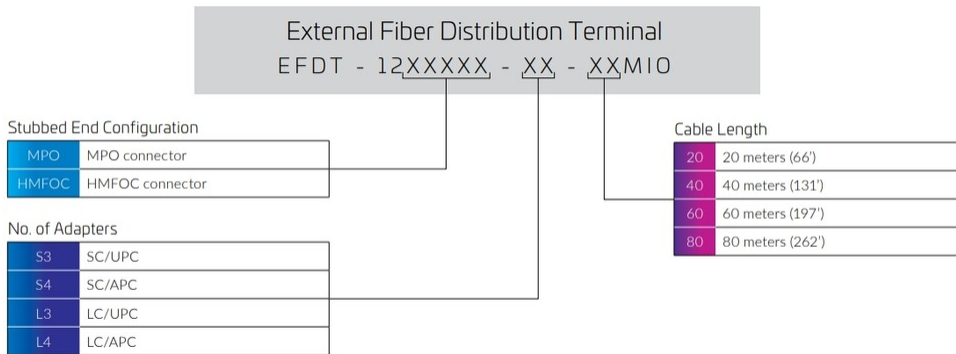

Material Specifications

Enclosure Material Type LSZH thermoplastic

Optical Specifications

Fiber Mode Singlemode

Fiber Type G.657.A2

Insertion Loss, Terminal Connector, typical 0.4 dB

Return Loss, Connector, minimum 55 dB

Environmental Specifications

Environmental Space Outdoor

Packaging and Weights

Packaging quantity 1

Packaging Type Box | Carton

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant



