

FL2-6P5CC605R



FL2000 Fiber Optic Adapter-pack, with 6 multimode ST/UPC simplex adapters, with pigtails, 5 meters

OBSOLETE

This product was discontinued on: March 1, 2018

Product Classification

Regional Availability	North America
Product Type	Fiber adapter pack with pigtails
Product Series	FL2000

General Specifications


Application	For use with FL2 panels
Adapter Color	Silver
Adapters, quantity, front	6
Body Style	Simplex Straight orientation
Color, front	Putty white
Interface	ST/UPC
Pigtail Assembly Type	Color-coded, 900 μ m Pigtail bundle
Pigtails Included, quantity	6
Total Fibers, quantity	6
Total Ports, quantity, front	6

Dimensions

Height	27.94 mm 1.1 in
Width	149.86 mm 5.9 in
Pigtail Length	5 m 16.404 ft

Ordering Tree

FL2-6P5CC605R

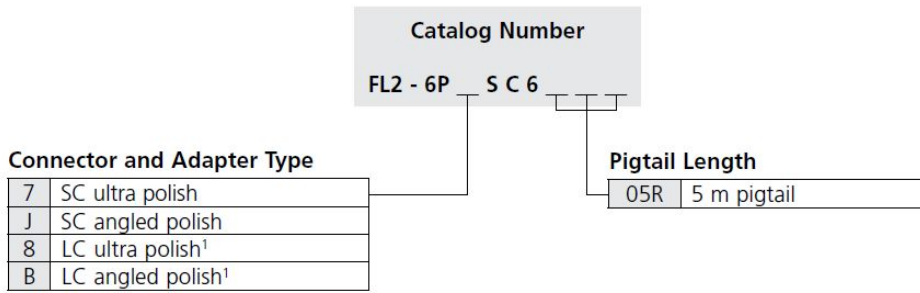

¹ LC 6paks are loaded with 12-fiber pigtails

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM2
Insertion Loss, maximum	0.3 dB
Return Loss, minimum	20 dB

Packaging and Weights

Packaging quantity	1
Packaging Type	Bag Carton

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

