

FL2-CD60048PN-4A00

FL2000 Fiber Termination/Splice Panel, pre-terminated with pigtails, 48 LC/UPC, multimode, 5RU, 19 in, putty white

OBSOLETE

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch/splice panel
Product Series	FL2000

General Specifications


Functionality	Patching Splicing
Adapter Packs Included, quantity	4
Cable Exit Location	Rear, left side Rear, right side
Color	Putty white
Color, front	Putty white
Growth Configuration	Partially loaded
Interface, front	LC/UPC
Patching Capacity, maximum	96
Rack Type	EIA 19 in
Rack Units	5
Shelf Movement	Hinged
Splicing Capacity, maximum	96
Total Ports, quantity	48

Dimensions

Height	222.25 mm 8.75 in
Width	482.6 mm 19 in
Depth	256.54 mm 10.1 in

Ordering Tree

FL2-CD60048PN-4A00

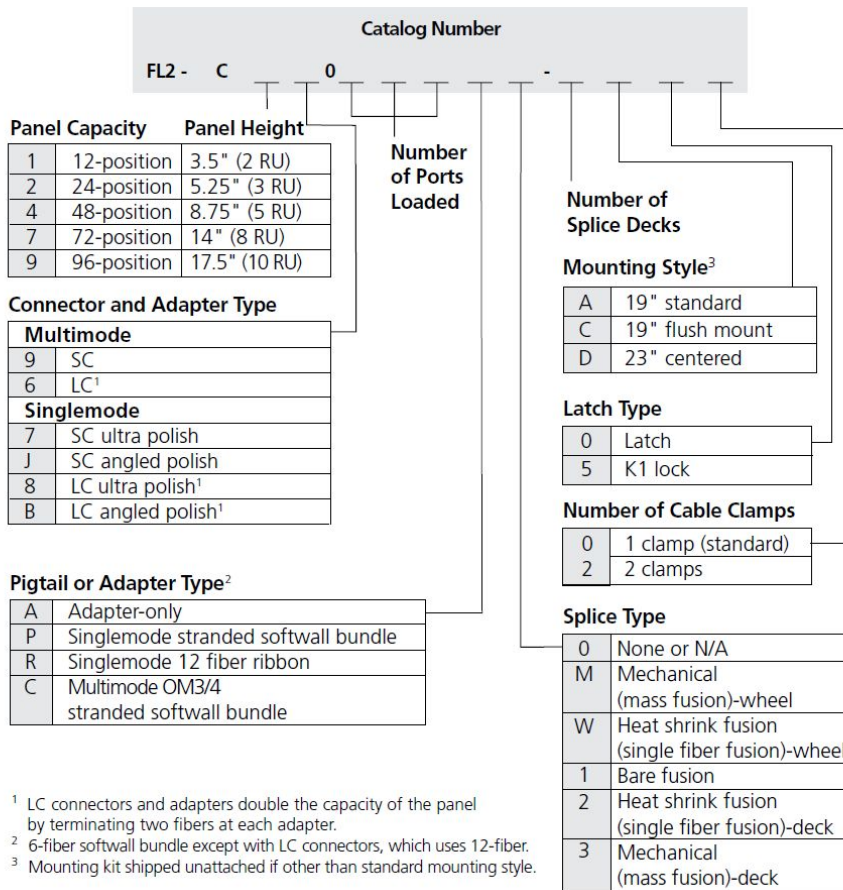

Material Specifications

Finish	Powder coated
Material Type	Steel

Optical Specifications

Fiber Mode	Multimode
-------------------	-----------

Environmental Specifications

Operating Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Storage Temperature	-40 °C to +85 °C (-40 °F to +185 °F)

Packaging and Weights

Included	Mounting hardware
Packaging quantity	1

FL2-CD60048PN-4A00

Regulatory Compliance/Certifications

Agency

CHINA-ROHS

ISO 9001:2015

REACH-SVHC

ROHS

UK-ROHS

Classification

Above maximum concentration value

Designed, manufactured and/or distributed under this quality management system

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

Compliant/Exempted

Compliant/Exempted

