

FMT-GRT080A00-A96P



FMT Fiber Termination Panel, with sliding tray, 96 LC/UPC, singlemode, 2RU, 19 in, putty white

Product Classification

| | |
|------------------------------|-------------------------------|
| Regional Availability | Latin America North America |
| Portfolio | CommScope® |
| Product Type | Fiber patch panel |
| Product Series | FMT |

General Specifications


| | |
|------------------------------|-----------------------|
| Functionality | Patching |
| Body Style | Symmetrical |
| Color | Black |
| Color, front | Putty white |
| Interface, front | LC/UPC |
| Rack Type | EIA 19 in EIA 23 in |
| Rack Units | 2 |
| Shelf Movement | Sliding |
| Total Ports, quantity | 96 |

Dimensions

| | |
|---------------|----------------------|
| Height | 88.9 mm 3.5 in |
| Width | 482.6 mm 19 in |
| Depth | 279.91 mm 11.02 in |

Ordering Tree

FMT-GRT080A00-A96P

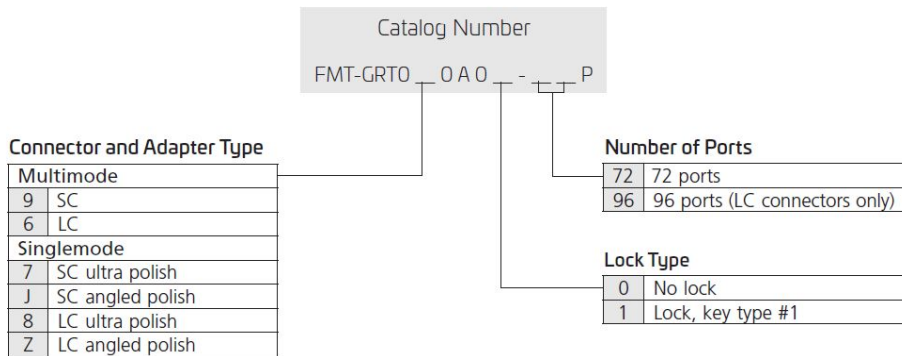

Material Specifications

Finish Powder coated

Material Type Steel

Optical Specifications

Fiber Mode Singlemode

Packaging and Weights

Included Mounting hardware

Packaging quantity 1

Regulatory Compliance/Certifications

Agency

CHINA-ROHS

REACH-SVHC

ROHS

UK-ROHS

Classification

Below maximum concentration value

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

Compliant

Compliant

