



FACT® Fiber Optic Splice Panel, gray, 3E high, loaded with 24 trays for holding up to 12 ANT type splices per tray

- Designed for use with the all-purpose all-front-access FIST-GR3 fiber frames supporting up to 2,688 LC or 1,344 SC connections in a single frame
- Reduced installation and maintenance time via the toolless snap-on design supporting both interconnect and cross-connect applications
- Flexible customization enabled by 4 chassis types (patch-only, patch-splice, pre-cabled and splice-only) to support all ODF applications
- High density through the single FACT element height (1E) being 30% less tall compared to the industry standard panel height (1HU)

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   EMEA   Latin America   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber splice panel
<b>Product Brand</b>	FACT®
<b>Product Series</b>	FACT

## General Specifications

<b>Functionality</b>	Splicing
<b>Application</b>	Compatible with FIST-GR3-style frames
<b>Body Style</b>	Symmetrical
<b>Color</b>	Gray
<b>Color, front</b>	Gray
<b>Growth Configuration</b>	Fully loaded
<b>Interface, front</b>	Unloaded
<b>Patching Capacity, maximum</b>	0
<b>Rack Type</b>	EIA 19 in
<b>Rack Units</b>	2.1
<b>Shelf Movement</b>	Sliding
<b>Splicing Capacity, maximum</b>	288
<b>Splicing Type</b>	ANT
<b>Total Ports, quantity</b>	0

# 760239968 | FACT-3ESPLA12

**Transmission Standards** ETSI EN 300 019-1-3 | IEC 61300-3-30


## Dimensions

**Height** 92.85 mm | 3.656 in  
**Width** 524 mm | 20.63 in  
**Depth** 283 mm | 11.142 in

## Splicing Configuration

NUMBER OF TRAYS PER FACT-CHASSIS				
	A04	S04	A12	S12
1E	12	12	8	6
2E	24	24	16	12
3E	36	36	24	18
4E	48	48	32	24

## Ordering Tree

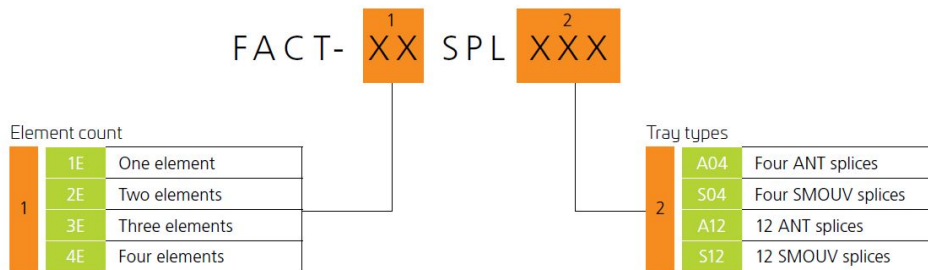

## Environmental Specifications

**Operating Temperature** -40 °C to +70 °C (-40 °F to +158 °F)  
**Storage Temperature** -20 °C to +85 °C (-4 °F to +176 °F)  
**Flammability Rating** UL 94 V-0

## Packaging and Weights

**Included** Mounting hardware  
**Packaging quantity** 1

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant/Exempted

