


CX4166-000 | FIST-GPS3-T-1

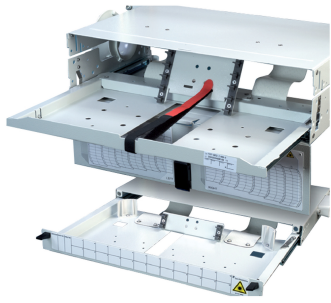

FIST-GPS3 Fiber Panel for holding up to 8 GPST Patch/Splice Trays, unloaded, 4RU, 15 in, gray

Product Classification

Regional Availability	EMEA
Portfolio	CommScope®
Product Type	Fiber patch/splice panel
Product Brand	FIST®
Product Series	FIST-GPS3

General Specifications

Functionality	Patching Splicing
Application	Used in FIST-GR3F-style frames only
Color	Gray
Color, front	Gray
Growth Configuration	Unloaded
Interface, front	Unloaded
Rack Type	EIA 15 in
Rack Units	4
Shelf Movement	Sliding

Dimensions

Height	167 mm 6.575 in
Width	381 mm 15 in
Depth	280 mm 11.024 in

Material Specifications

Finish	Powder coated
Material Type	Galvanized steel

CX4166-000 | FIST-GPS3-T-1

Environmental Specifications

Operating Temperature	-5 °C to +45 °C (+23 °F to +113 °F)
Storage Temperature	-30 °C to +60 °C (-22 °F to +140 °F)
Relative Humidity	Up to 93%, non-condensing

Packaging and Weights

Included	Mounting hardware
Packaging quantity	1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

