


## EHD 24 port LC field term splice cassette

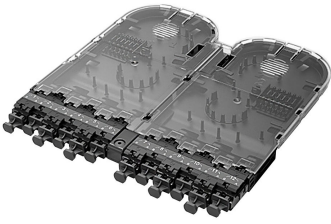

### Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   EMEA   Latin America   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber cassette
<b>Product Series</b>	EHD

### General Specifications

<b>Color, front</b>	Black
<b>Interface, front</b>	LC/UPC
<b>Interface, rear</b>	No pigtail
<b>Total Fibers, quantity</b>	24

### Dimensions

<b>Height</b>	11.43 mm   0.45 in
<b>Width</b>	169.672 mm   6.68 in
<b>Depth</b>	163.83 mm   6.45 in

### Environmental Specifications

<b>Safety Standard</b>	CE   CSA   UL
------------------------	---------------

### Packaging and Weights

<b>Packaging quantity</b>	1
<b>Weight, net</b>	0.159 kg   0.35 lb

### Regulatory Compliance/Certifications

**Agency**

CHINA-ROHS  
ISO 9001:2015  
REACH-SVHC  
ROHS  
UK-ROHS

**Classification**

Below maximum concentration value  
Designed, manufactured and/or distributed under this quality management system  
Compliant as per SVHC revision on [www.commscope.com/ProductCompliance](http://www.commscope.com/ProductCompliance)  
Compliant  
Compliant

