


760242690 | PNL-CS-24LCX-RPT

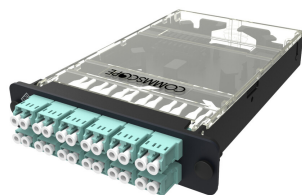

LazrSPEED® Splicing cassette, OM4, 24 LC/UPC, Ribbon

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber cassette with ribbon pigtail
Product Brand	LazrSPEED®

General Specifications

Adapter Color	Aqua
Interface, front	LC/UPC
Interface, rear	Ribbon pigtail
Total Fibers, quantity	24
Total Ports, quantity, front	12

Dimensions

Height	28.956 mm 1.14 in
Width	104.648 mm 4.12 in
Depth	165.354 mm 6.51 in
Pigtail Length	1.5 m 4.921 ft

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM4, LazrSPEED® 550
Insertion Loss, typical	0.3 dB
Return Loss, minimum	25 dB

Environmental Specifications

Safety Standard	UL
------------------------	----

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

