


FL2-24RPNL

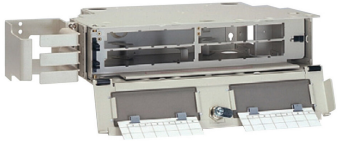

FL2000 Fiber Termination Panel, unloaded, 24 Ports, 2RU, 19 in, putty white

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch panel
Product Series	FL2000

General Specifications

Functionality	Patching
Color	Putty white
Growth Configuration	Unloaded
Interface, front	Unloaded
Rack Type	EIA 19 in
Rack Units	2
Shelf Movement	Hinged
Splicing Capacity, maximum	0
Total Ports, quantity	24

Dimensions

Height	88.9 mm 3.5 in
Width	482.6 mm 19 in
Depth	257.5 mm 10.138 in

Material Specifications

Finish	Powder coated
Material Type	Steel

Optical Specifications

Fiber Mode	Singlemode
-------------------	------------

FL2-24RPNL

Environmental Specifications

Operating Temperature -40 °C to +70 °C (-40 °F to +158 °F)

Storage Temperature -40 °C to +85 °C (-40 °F to +185 °F)

Packaging and Weights

Included Mounting hardware

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

