

FL2-R720072A0-0A00

FL2000 Fiber Termination Panel, 72 FC/UPC, singlemode, 5RU, 19 in, putty white

OBSOLETE

This product was discontinued on: March 1, 2018

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch panel
Product Series	FL2000

General Specifications


Functionality	Patching
Adapter Packs Included, quantity	12
Color	Putty white
Color, front	Putty white
Growth Configuration	Fully loaded
Interface, front	FC
Interface Feature, front	Standard
Patching Capacity, maximum	72
Rack Type	EIA 19 in
Rack Units	5
Shelf Movement	Hinged
Splicing Capacity, maximum	0
Total Ports, quantity	72

Dimensions

Height	222.25 mm 8.75 in
Width	482.6 mm 19 in
Depth	256.54 mm 10.1 in

Ordering Tree

FL2-R720072A0-0A00

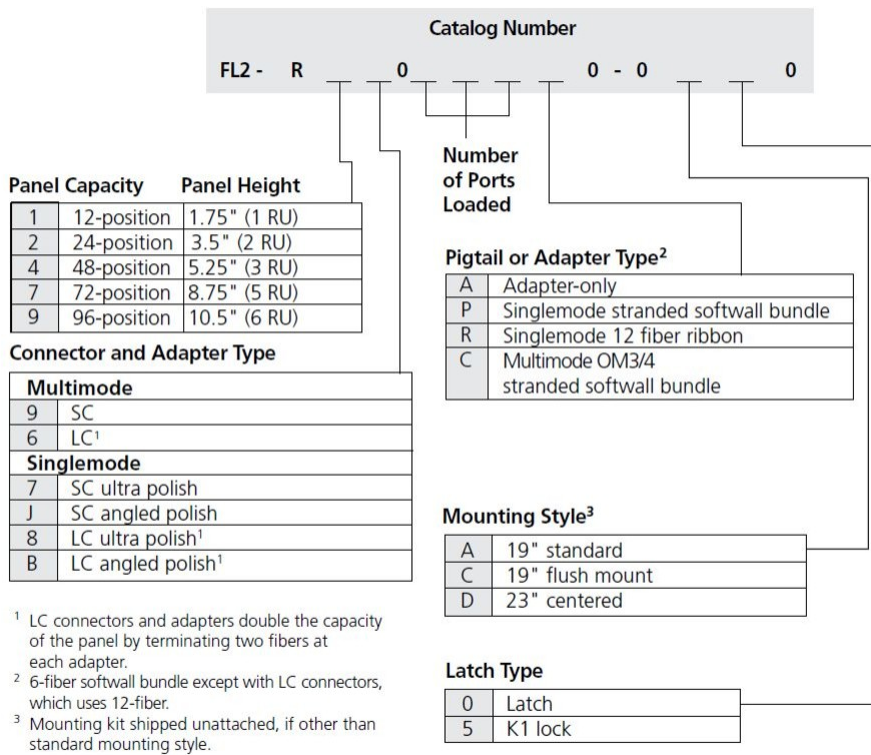

Material Specifications

Finish Powder coated

Material Type Steel

Optical Specifications

Fiber Mode Singlemode

Environmental Specifications

Operating Temperature -40 °C to +70 °C (-40 °F to +158 °F)

Storage Temperature -40 °C to +85 °C (-40 °F to +185 °F)

Packaging and Weights

Included Mounting hardware

Packaging quantity 1

Regulatory Compliance/Certifications

FL2-R720072A0-0A00

Agency

CHINA-ROHS

REACH-SVHC

ROHS

**Classification**

Above maximum concentration value

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

Compliant/Exempted