


FKWMPMPAH

Base Product

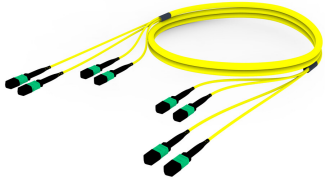

Singlemode MPO (Unpinned) to MPO (Unpinned), InstaPATCH® 360 Armored Pre-terminated Trunk Cable, 48-Fiber, Low Smoke Zero Halogen

OBSOLETE

This product was discontinued on: October 7, 2024

Product Classification

Regional Availability	Asia Australia/New Zealand China India Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	SYSTIMAX InstaPATCH® 360
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration Not available in the United States or Canada

General Specifications


Color, boot A	Black
Color, connector A	Green
Color, boot B	Black
Color, connector B	Green
Construction Type	Armored Stranded
Furcation Color	Yellow
Interface, Connector A	MPO-12/APC Female
Interface, Connector B	MPO-12/APC Female
Jacket Color	Yellow
Polarity	Method B (LL)
Fibers per Subunit, quantity	12
Total Fibers, quantity	48

Dimensions

FKWMPMPAH

Breakout Length	33 in
Cable Assembly Length Range (m)	3 – 999
Cable Assembly Length Range (ft)	10 – 999

Ordering Tree

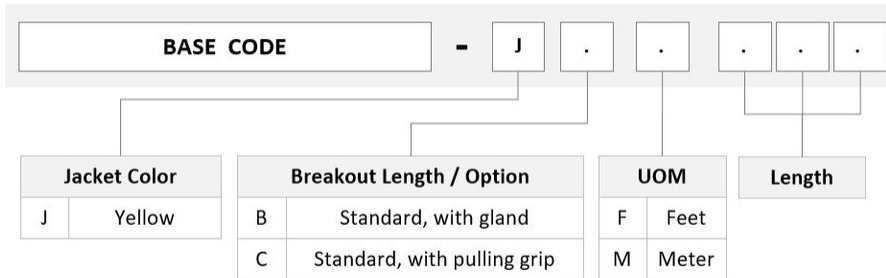

Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0 ° 4.40 lb @ 90 °
--	---------------------------------

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.652.D G.657.A1, TeraSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Dual Rated LSZH/Riser Indoor

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

FKWMPMPAH



Included Products

- 760119917
N-048-MZ-8W-F12YL - Fiber indoor cable, TeraSPEED® Low Smoke Zero Halogen Riser MPO Trunk, interlocking aluminum armored, Singlemode G.652.D and G.657.A1, 48 fiber multi-unit with 12 fiber subunits, Feet jacket marking, Yellow jacket color
- 860366137 - MPO12, LOW LOSS, FEMALE, Singlemode, GREEN, 3mm