


FLWSASAAD

Base Product

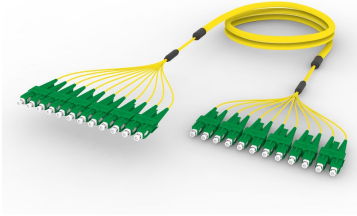

Singlemode SC/APC to SC/APC, InstaPATCH® 360 Ruggedized Fiber Fanout Cable Assembly, 12-Fiber, Plenum

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Ruggedized fanout
Product Brand	SYSTIMAX InstaPATCH® 360
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications


Color, connector A	Green
Color, connector B	Green
Construction Type	Stranded
Furcation Color	Yellow
Interface, Connector A	SC/APC
Interface, Connector B	SC/APC
Fibers per Subunit, quantity	12
Total Fibers, quantity	12

Dimensions

Cable Assembly Length Range (m)	3 – 999
Cable Assembly Length Range (ft)	8 – 999

Ordering Tree

FLWSASAAD

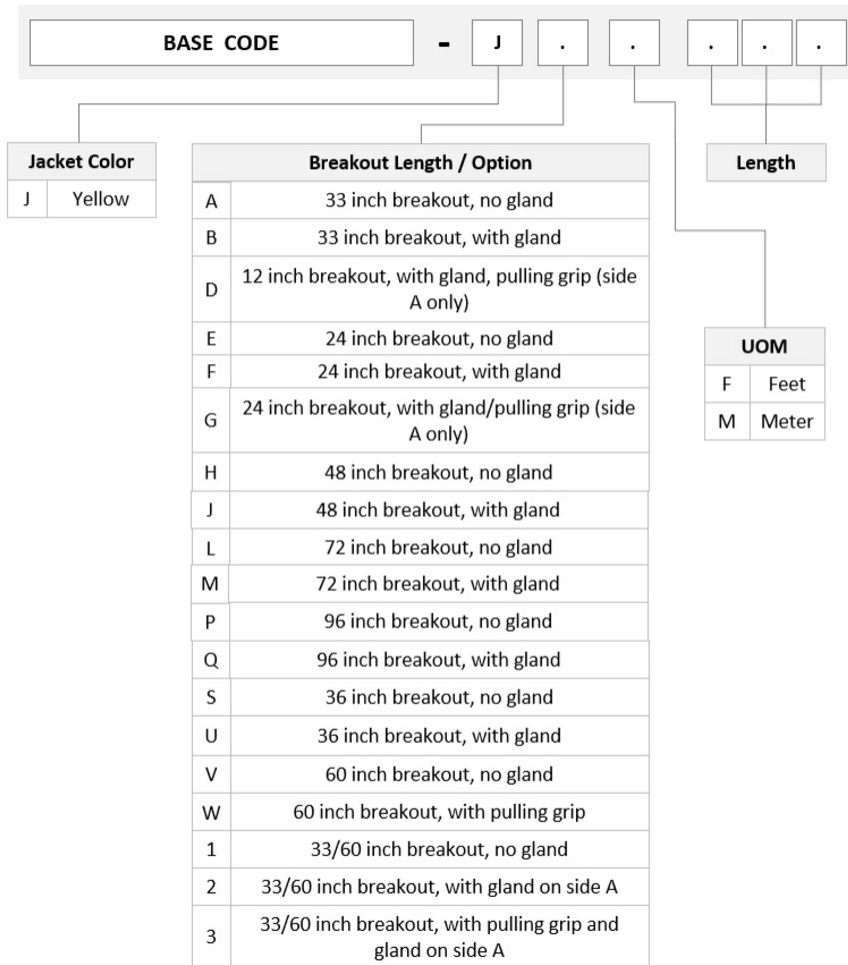

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0° | 4.40 lb @ 90°

Optical Specifications

Fiber Mode Singlemode

Fiber Type G.652.D | G.657.A1, TeraSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Plenum

Regulatory Compliance/Certifications

FLWSASAAD

Agency

ISO 9001:2015

Classification

Designed, manufactured and/or distributed under this quality management system

Included Products

- 760237963
P-012-MP-8G1-F12YL – Fiber indoor cable, Plenum for MPO Trunks, 12 fiber, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color
- 860648957 – SC/APC Connector, Singlemode, Green