


U3VQXQXQH

Base Product

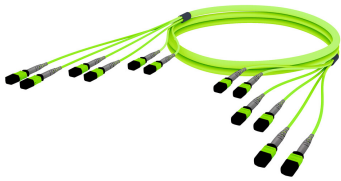

Ultra Low Loss (ULL) OM5 MPO QSFP (Pinned) to MPO QSFP (Pinned), Pre-terminated Cable, MPO8, 48-Fiber, Low Smoke Zero Halogen (LSZH)

This product will be discontinued on: April 30, 2024

Replaced By:

U3VQXQXTH

Ultra Low Loss (ULL) OM5 MPO8 (Pinned) to MPO8 (Pinned), Fiber Trunk Cable Assembly, 48-Fiber, LZSH B2ca

Product Classification

Regional Availability	Europe
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	Not available in the United States or Canada

General Specifications

Color, boot A	Gray
Color, connector A	Lime green
Color, boot B	Gray
Color, connector B	Lime green
Construction Type	Stranded
Furcation Color	Lime green
Interface, Connector A	MPO-08/UPC Male
Interface Feature, connector A	QSFP configuration
Interface, Connector B	MPO-08/UPC Male
Interface Feature, connector B	QSFP configuration
Jacket Color	Lime green
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	8

U3VQXQXQH

Total Fibers, quantity 48


Dimensions

Breakout Length 33 in

Cable Assembly Length Range (m) 3 – 999

Cable Assembly Length Range (ft) 10 – 999

Ordering Tree

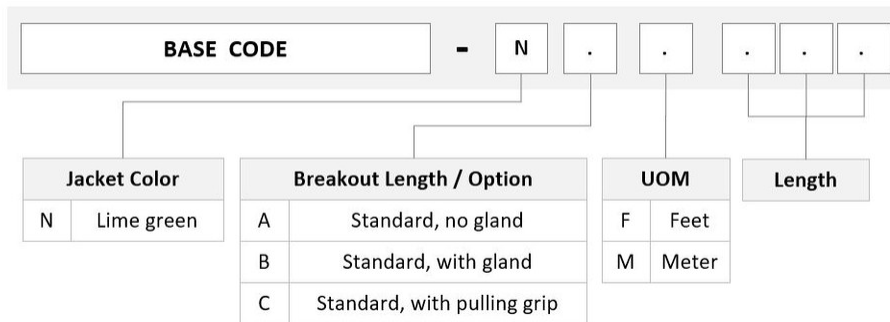

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Multimode

Fiber Type OM5, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Low Smoke Zero Halogen (LSZH)

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted

U3VQXQXQH

UK-ROHS

Compliant/Exempted



Included Products

- | | | |
|-----------------------------------|---|--|
| 760239608
N-048-MP-5G-F12LM/B2 | - | Fiber indoor cable, LazrSPEED®, Low Smoke Zero Halogen Riser MPO Trunk, 48 fibers, 12 fiber subunits, Multimode OM5, Gel-free, Feet jacket marking, Lime green jacket color, B2ca Flame rating |
| 860633312 | - | MPO8, ULTRA LOW LOSS, MALE, OM5, LIME, 3mm |