


U4XLCLCCF

Base Product

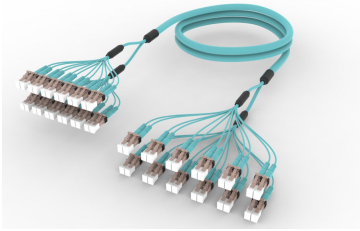

Ultra Low Loss ULL LazrSPEED® 550 LC/UPC to LC/UPC Ruggedized fanout Cable, 24-Fiber, LSZH, 12 fiber PmP 2.0 mm /B2ca

Product Classification

Regional Availability

Asia | Australia/New Zealand | Europe | Latin America | Middle East/Africa | North America

Portfolio

CommScope®

Product Type

Ruggedized fanout

Product Brand

SYSTIMAX ULL

Ordering Note

For additional jacket colors, please contact a CommScope Sales Representative | For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

General Specifications

Color, boot A

Blue

Color, connector A

Black

Color, boot B

Blue

Color, connector B

Black

Construction Type

Stranded

Furcation Color

Aqua

Interface, Connector A

LC/UPC

Interface Feature, connector A

ULL

Interface, Connector B

LC/UPC

Interface Feature, connector B

ULL

Jacket Color

Aqua

Fibers per Subunit, quantity

12

Total Fibers, quantity

24

Dimensions

Cable Assembly Length Range (m)


3 – 305

Cable Assembly Length Range (ft)

10 – 999

U4XLCLCCF

Ordering Tree

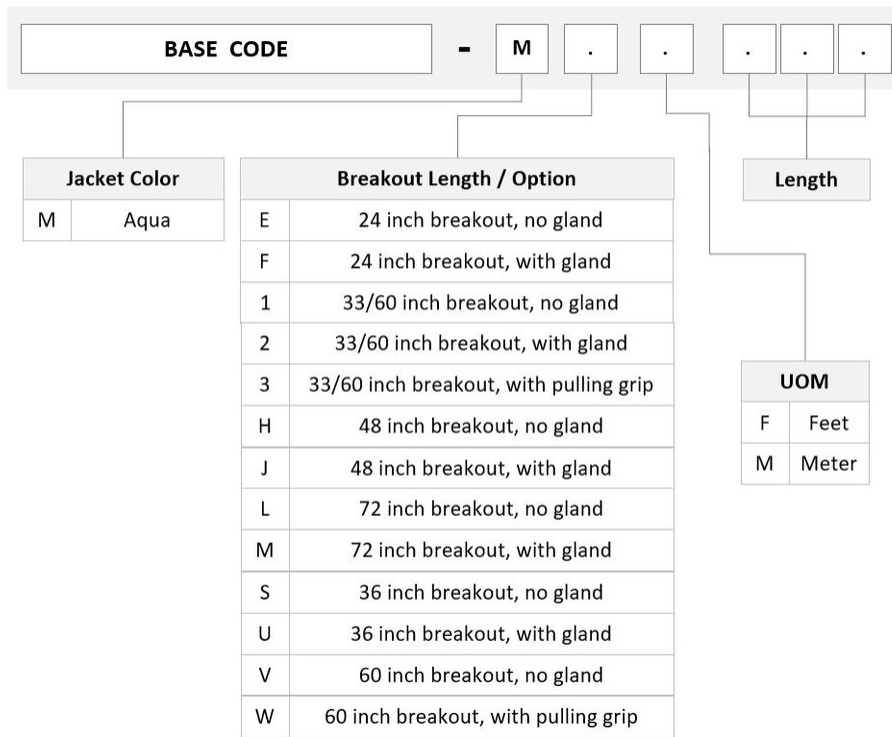

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM4, LazrSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
EN50575 CPR Cable EuroClass Fire Performance	B2ca
Environmental Space	Indoor Low Smoke Zero Halogen (LSZH)

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

U4XLCLCCF

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant

