


U4XLCLCCL

Base Product

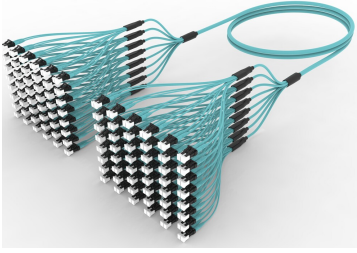

Ultra Low Loss ULL LazrSPEED® 550 LC/UPC to LC/UPC Ruggedized fanout Cable, 96-Fiber, LSZH, 12 fiber PmP 2.0 mm /B2ca

Product Classification

Regional Availability

Asia | Australia/New Zealand | Europe | Latin America | Middle East/Africa | North America

Portfolio

CommScope®

Product Type

Ruggedized fanout

Product Brand

SYSTIMAX ULL

Ordering Note

For additional jacket colors, please contact a CommScope Sales Representative | For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

General Specifications

Color, boot A

Blue

Color, connector A

Black

Color, boot B

Blue

Color, connector B

Black

Construction Type

Stranded

Furcation Color

Aqua

Interface, Connector A

LC/UPC

Interface Feature, connector A

ULL

Interface, Connector B

LC/UPC

Interface Feature, connector B

ULL

Jacket Color

Aqua

Fibers per Subunit, quantity

12

Total Fibers, quantity

96

Dimensions

Cable Assembly Length Range (m)


3 – 305

U4XLCLCCL

Cable Assembly Length Range (ft)

10 – 999

Ordering Tree

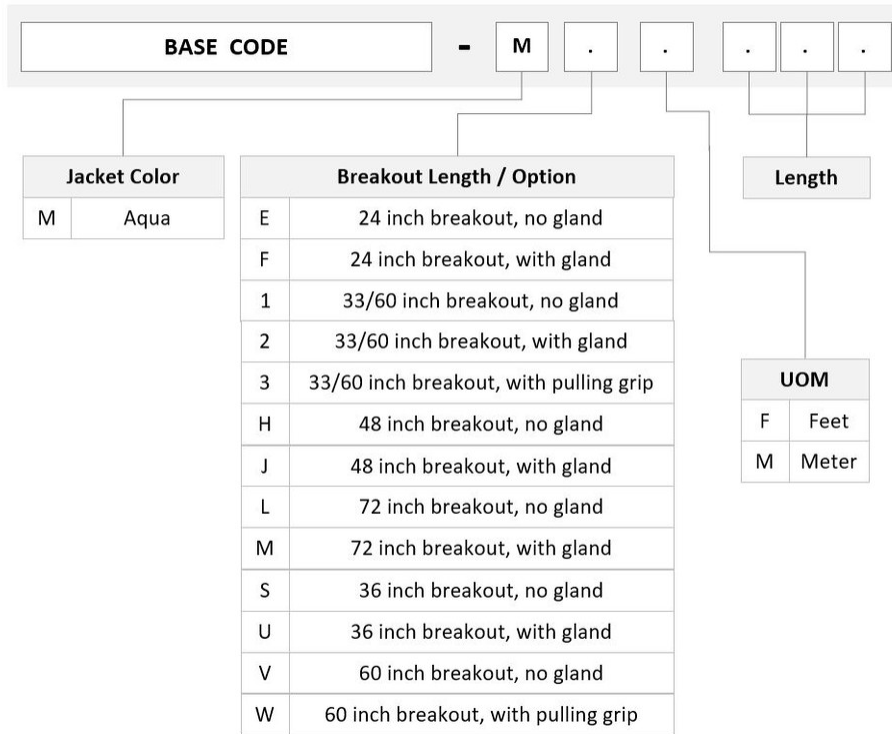

Optical Specifications

| | |
|-------------------|-----------------|
| Fiber Mode | Multimode |
| Fiber Type | OM4, LazrSPEED® |

Environmental Specifications

| | |
|---|--|
| Operating Temperature | -10 °C to +60 °C (+14 °F to +140 °F) |
| EN50575 CPR Cable EuroClass Fire Performance | B2ca |
| Environmental Space | Indoor Low Smoke Zero Halogen (LSZH) |

Regulatory Compliance/Certifications

| Agency | Classification |
|------------|-----------------------------------|
| ANATEL | Compliant |
| CHINA-ROHS | Below maximum concentration value |

U4XLCLCCL

| | |
|---------------|--|
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |
| REACH-SVHC | Compliant as per SVHC revision on www.commscope.com/ProductCompliance |
| ROHS | Compliant |
| UK-ROHS | Compliant |

