


Base Product

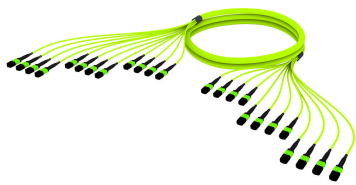

Ultra Low Loss ULL LazrSPEED® 550 OM5 MPO(Unpinned) to MPO (Pinned) Pre-terminated Trunk Cable, MPO12, 144-Fiber, LSZH, 12 fiber PmP 2.0 mm Dca

Product Classification

| | |
|-----------------------|--|
| Regional Availability | Asia Australia/New Zealand Europe Latin America Middle East/Africa North America |
| Portfolio | CommScope® |
| Product Type | Fiber trunk cable assembly |
| Product Brand | SYSTIMAX ULL |
| Ordering Note | For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration |

General Specifications


| | |
|------------------------------|-------------------------|
| Color, boot A | Black |
| Color, connector A | Black |
| Color, boot B | Black |
| Color, connector B | Black |
| Construction Type | Stranded |
| Furcation Color | Lime green |
| Interface, Connector A | MPO-12/UPC Female |
| Interface, Connector B | MPO-12/UPC Male |
| Jacket Color | Lime green |
| Polarity | Method B Enhanced (ULL) |
| Fibers per Subunit, quantity | 12 |
| Total Fibers, quantity | 144 |

Dimensions

UJVMPMXCM

| | |
|----------------------------------|----------|
| Breakout Length | 33 in |
| Cable Assembly Length Range (m) | 3 – 999 |
| Cable Assembly Length Range (ft) | 10 – 999 |

Ordering Tree

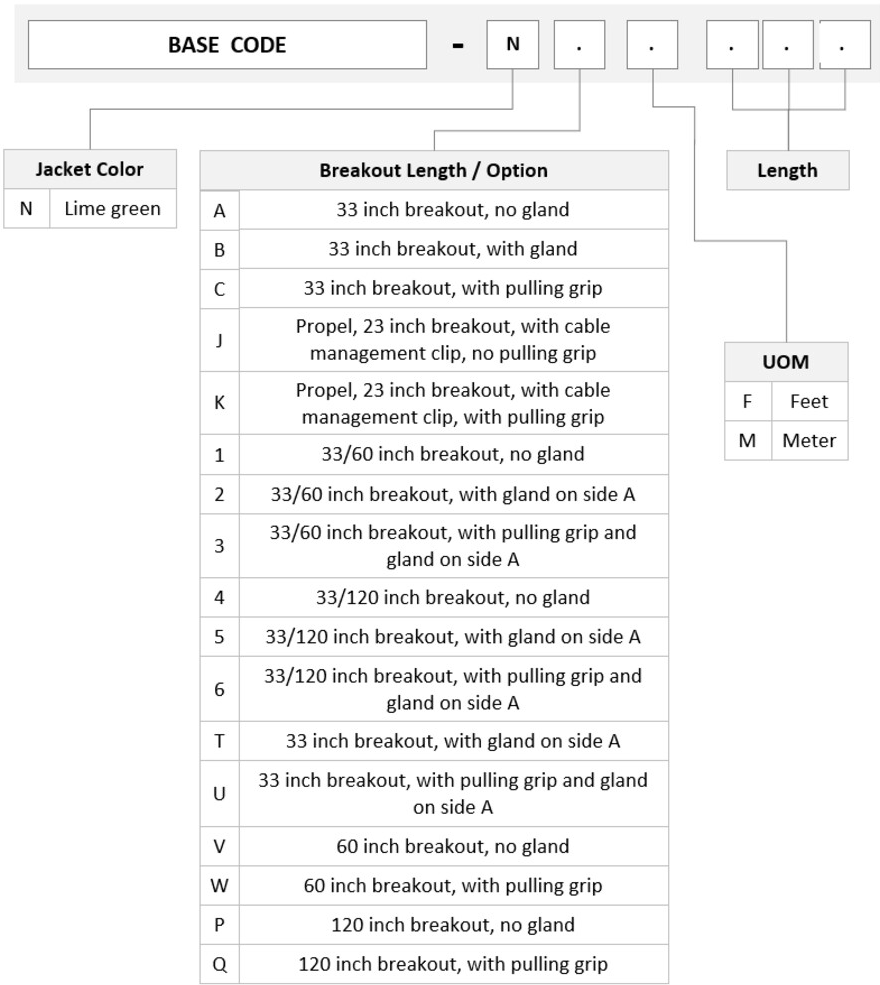

Optical Specifications

| | |
|------------|-----------------|
| Fiber Mode | Multimode |
| Fiber Type | OM5, LazrSPEED® |

Environmental Specifications

| | |
|-----------------------|--------------------------------------|
| Operating Temperature | -10 °C to +60 °C (+14 °F to +140 °F) |
|-----------------------|--------------------------------------|

EN50575 CPR Cable EuroClass Fire Performance

Dca

Environmental Space

Dual Rated LSZH/Riser | Indoor

Regulatory Compliance/Certifications

| Agency | Classification |
|---------------|--|
| ANATEL | Compliant |
| CHINA-ROHS | Above maximum concentration value |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |
| REACH-SVHC | Compliant as per SVHC revision on www.commscope.com/ProductCompliance |
| ROHS | Compliant/Exempted |
| UK-ROHS | Compliant/Exempted |



Included Products

| | | |
|--------------------------------------|---|---|
| 760244161 N-144-MP-5G-F12LM/20T/D | - | Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 144 fiber multi-unit with 12 fiber 2.0mm subunits, Gel-free, Multimode OM5, Feet jacket marking, Lime green jacket color, Dca flame rating |
| 860659008 | - | MPO12, ULL, MALE, OM5, LIME, 2MM |
| 860659014 | - | MPO12, ULL, FEMALE, OM5, LIME, 2MM |