


Base Product

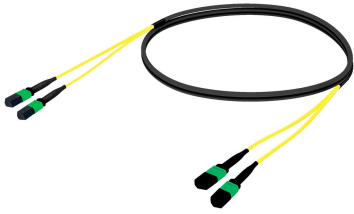

Ultra Low Loss (ULL) Singlemode, MPO12 Unpinned to MPO12 Unpinned, Fiber Trunk Cable Assembly, 24-Fiber, Indoor/Outdoor Armored, Low Smoke Zero Halogen/Riser

Product Classification

Regional Availability	Asia Australia/New Zealand China India Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Color, boot A	Black
Color, connector A	Green
Color, boot B	Black
Color, connector B	Green
Construction Type	Armored Stranded
Furcation Color	Yellow
Interface, Connector A	MPO-12/APC Female
Interface, Connector B	MPO-12/APC Female
Jacket Color	Black
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	12
Total Fibers, quantity	24

Dimensions

UKGMPPDF

Included Products

- 760238841
Z-024-MZ-8G-F12BK - Fiber Indoor/Outdoor cable, Low Smoke Zero Halogen Riser MPO Trunk, interlocking aluminum armored, 24 fiber multi-unit with 12 fiber subunits, Singlemode G.657.A2, Feet jacket marking, Black jacket color
- 860638318 - MPO12, ULTRA LOW LOSS, FEMALE, Singlemode, GREEN, 3mm