


## Base Product

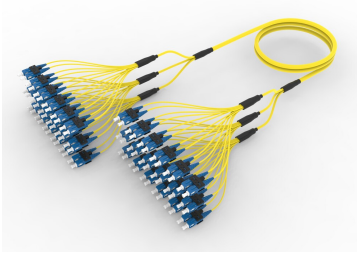

Ultra Low Loss ULL TeraSPEED® SC/UPC to SC/UPC Ruggedized fanout Cable, 36-Fiber, LSZH, 12 fiber PmP 2.0 mm Dca

## Product Classification

|                              |  |
|------------------------------|--|
| <b>Regional Availability</b> | Asia   Australia/New Zealand   Europe   Latin America   Middle East/Africa   North America   |
| <b>Portfolio</b>             | CommScope®   |
| <b>Product Type</b>          | Ruggedized fanout  |
| <b>Product Brand</b>         | SYSTIMAX ULL   |
| <b>Ordering Note</b>         | For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration |

## General Specifications

|                                       |          |
|---------------------------------------|----------|
| <b>Color, boot A</b>                  | Blue     |
| <b>Color, connector A</b>             | Blue     |
| <b>Color, boot B</b>                  | Blue     |
| <b>Color, connector B</b>             | Blue     |
| <b>Construction Type</b>              | Stranded |
| <b>Furcation Color</b>                | Yellow   |
| <b>Interface, Connector A</b>         | SC/UPC   |
| <b>Interface Feature, connector A</b> | ULL      |
| <b>Interface, Connector B</b>         | SC/UPC   |
| <b>Interface Feature, connector B</b> | ULL      |
| <b>Jacket Color</b>                   | Yellow   |
| <b>Fibers per Subunit, quantity</b>   | 12       |
| <b>Total Fibers, quantity</b>         | 36       |

## Dimensions

|  |         |
|--|---------|
| <b>Cable Assembly Length Range (m)</b> | 3 – 305 |
|--|---------|

## Ordering Tree



## Optical Specifications

**Fiber Mode**

Singlemode

**Fiber Type**

G.657.A2, TeraSPEED®

## Environmental Specifications

**Operating Temperature**

-10 °C to +60 °C (+14 °F to +140 °F)

**EN50575 CPR Cable EuroClass Fire Performance**

Dca

**Environmental Space**

Dual Rated LSZH/Riser | Indoor

## Regulatory Compliance/Certifications

**Agency**

**Classification**

ANATEL

Compliant

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system



## Included Products

760242309  
N-036-MP-8G-F12YL/20T/D

- Fiber indoor cable, Low Smoke Zero Halogen Riser MPO Trunk, 36 fiber multi-unit with 12 fiber 2.0 mm subunits, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color, Dca flame rating