


# AGGMPMPCG

## Base Product

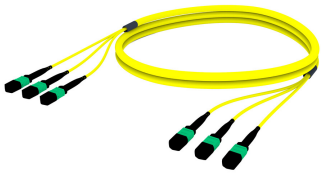

Ultra Low Loss ULL TeraSPEED® MPO(Unpinned) to MPO(Unpinned) Pre-terminated Trunk Cable, MPO12, 36-Fiber, Plenum, 12 fiber PmP 2.0 mm Dca, Method A

## Product Classification

### Regional Availability

Asia | Australia/New Zealand | Europe | Latin America | Middle East/Africa | North America

### Portfolio

CommScope®

### Product Type

Fiber trunk cable assembly

### Ordering Note

For additional jacket colors, please contact a CommScope Sales Representative | For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

## General Specifications

### Color, boot A

Black

### Color, connector A

Green

### Color, boot B

Black

### Color, connector B

Green

### Construction Type

Stranded

### Furcation Color

Yellow

### Interface, Connector A

MPO-12/APC Female

### Interface, Connector B

MPO-12/APC Female

### Jacket Color

Yellow

### Polarity

Method A

### Fibers per Subunit, quantity

12

### Total Fibers, quantity

36

## Dimensions

### Breakout Length

33 in

### Cable Assembly Length Range (m)

3 – 999

### Cable Assembly Length Range (ft)

10 – 999

# AGGMPPMPCG

## Ordering Tree



## Optical Specifications

<b>Fiber Mode</b>	Singlemode
<b>Fiber Type</b>	G.657.A2, TeraSPEED®

## Environmental Specifications

<b>Operating Temperature</b>	-10 °C to +60 °C (+14 °F to +140 °F)
<b>EN50575 CPR Cable EuroClass Fire Performance</b>	Dca
<b>Environmental Space</b>	Indoor   Plenum

## Regulatory Compliance/Certifications

# AGGMPPMPCG

---

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



## Included Products

760242053	-	Fiber indoor cable, Plenum MPO Trunk, 36 fiber multi-unit with 12 fiber subunits, Singlemode G.
P-036-MP-8G-F12YL/20T		657.A2/B2, Feet jacket marking, Yellow jacket color
860659016	-	MPO12, ULL, FEMALE, SM, GREEN, 2MM