


UNXMXLCAF

Base Product

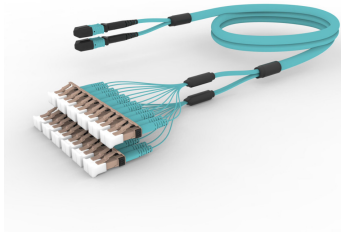

Ultra Low Loss OM4 MPO12 Pinned to LC/UPC Uniboot 24-Fiber InstaPATCH® 360 Ruggedized Fanout Cable, Low Smoke Zero Halogen

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Ruggedized fanout
Product Brand	SYSTIMAX InstaPATCH® 360
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Color, boot A	Black
Color, connector A	Aqua
Color, boot B	Aqua
Color, connector B	Beige
Construction Type	Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-12/UPC Male
Interface, Connector B	LC/UPC
Interface Feature, connector B	Uniboot
Jacket Color	Aqua
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	12
Total Fibers, quantity	24

Dimensions


Cable Assembly Length Range (m)	3 – 999
--	---------

UNXMXLCAF

Cable Assembly Length Range (ft)

7 – 999

Ordering Tree

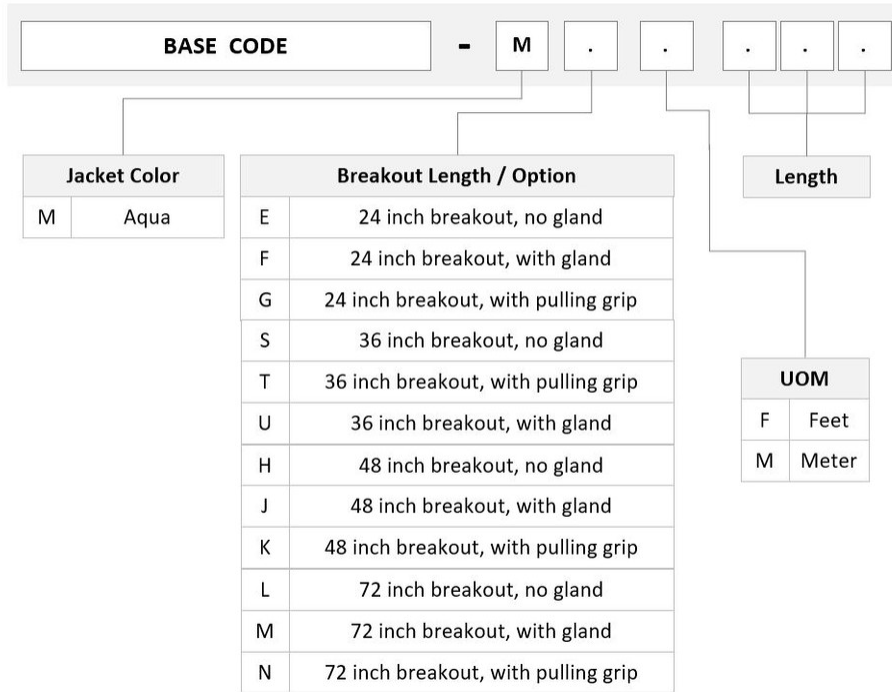

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0° | 4.40 lb @ 90°

Optical Specifications

Fiber Mode Multimode

Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Dual Rated LSZH/Riser | Indoor

Regulatory Compliance/Certifications

Agency **Classification**

ANATEL Compliant

UNXMXLCAF

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system



Included Products

- | | | |
|----------------------------------|---|--|
| 460133515 | - | LazrSPEED® Pre-Radiused LC Connector for 1.6 mm Fiber, duplex Multimode, beige |
| 760067488
N-024-MP-5K-F12AQ/D | - | Fiber indoor cable, LazrSPEED®, Low Smoke Zero Halogen Riser MPO Trunk, 24 fiber with 12 fiber subunits, Gel-free, Multimode OM4, Feet jacket marking, Aqua jacket color, Dca flame rating |
| 860366228 | - | MPO12, ULTRA LOW LOSS, MALE, OM3/4, AQUA, 3mm |