


UQV2XLUHF

Base Product

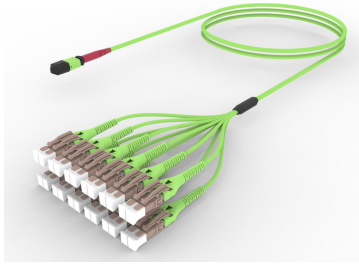

Ultra Low Loss OM5 MPO24 Pinned to LC/UPC Uniboot 24-Fiber Plenum Array Cord

Product Classification

Regional Availability	Europe Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber array cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications


Color, boot A	Red
Color, connector A	Lime green
Color, boot B	Lime green
Color, connector B	Beige
Construction Type	Stranded
Furcation Color	Lime green
Interface, Connector A	MPO-24/UPC Male
Interface, Connector B	LC/UPC
Interface Feature, connector B	Uniboot
Jacket Color	Lime green
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	24
Total Fibers, quantity	24

Dimensions

Cable Assembly Length Range (m)	3 – 999
Cable Assembly Length Range (ft)	10 – 999

UQV2XLUHF

Ordering Tree

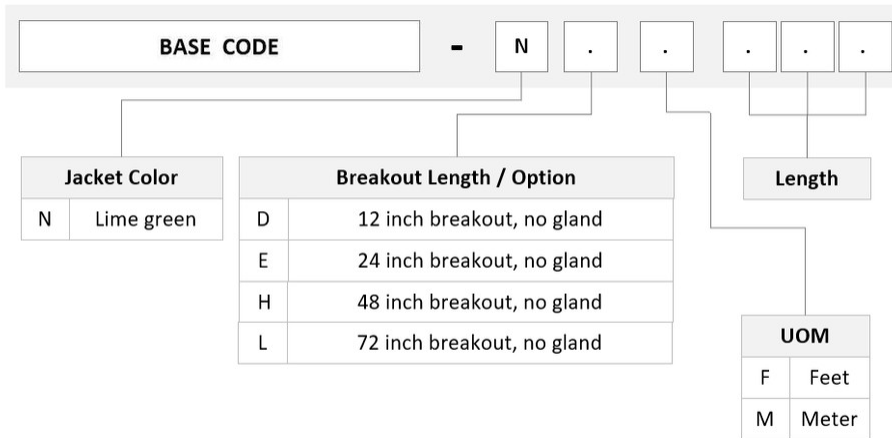

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Multimode

Fiber Type OM5, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Indoor | Plenum

Regulatory Compliance/Certifications

Agency

ISO 9001:2015

Classification

Designed, manufactured and/or distributed under this quality management system

Included Products

- 760235986 P-024-MP-5G-F36LM – Fiber indoor cable, LazrSPEED® Plenum MPO Light Duty for Patchcords, 24 fiber, Multimode OM5, Feet jacket marking, Lime green jacket color
- 860634625 – LazrSPEED® Elite MPO Male 24 Fiber Connector, lime green
- 860650410 – LazrSPEED® LC UniBoot 2.0 mm Multimode/LC UNIBOOT CONNECTOR KIT