


URVMXLCGD

Base Product

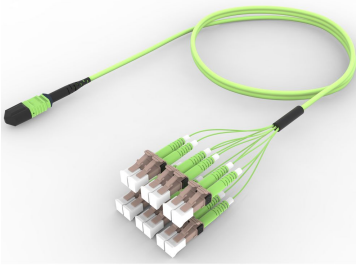

Ultra Low Loss (ULL) OM5 MPO12 (Pinned) to LC/UPC, Fiber Extension Cable Assembly, 12-Fiber, Low Smoke Zero Halogen

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Fiber array cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications


Color, boot A	Black
Color, connector A	Lime green
Color, boot B	Lime green
Color, connector B	Beige
Construction Type	Stranded
Furcation Color	Lime green
Interface, Connector A	MPO-12/UPC Male
Interface, Connector B	LC/UPC
Jacket Color	Lime green
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	12
Total Fibers, quantity	12

Dimensions

URVMXLCGD

Breakout Length	33 in
Cable Assembly Length Range (m)	3 – 999
Cable Assembly Length Range (ft)	10 – 999

Ordering Tree

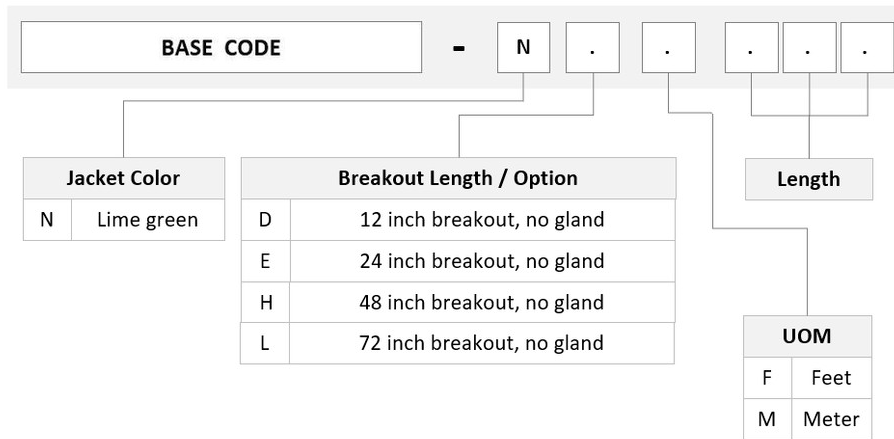

Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0° 4.40 lb @ 90°
--	-------------------------------

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM5, LazrSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Indoor Low Smoke Zero Halogen (LSZH)

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance

URVMXLCGD

ROHS Compliant/Exempted

UK-ROHS Compliant/Exempted



Included Products

- 760229039
N-012-MP-5G-F30LM/D – Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser Light Duty for MPO Patchcords, 12 fiber, Multimode OM5, Gel-free, Feet jacket marking, Lime green jacket color, Dca Flame rating
- 860617240 – MPO12, ULTRA LOW LOSS, MALE, OM5, LIME, 3mm
- 860649627 – LC/UPC Connector, Multimode, Beige, Short Boot