


# URX2CMPHF

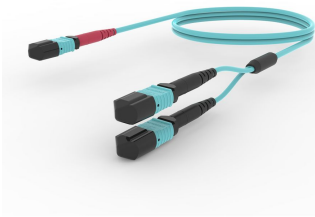

Ultra Low Loss OM4, MPO24 (Unpinned) to MPO12 (Unpinned), Fiber Extension Cable Assembly, 24-Fiber, Low Smoke Zero Halogen

## Product Classification

Regional Availability	Australia/New Zealand   Europe   Latin America   Middle East/Africa
Portfolio	CommScope®
Product Type	Fiber array cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	Can only be used with CXP transceivers   For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications

Color, boot A	Red
Color, boot B	Black
Color, connector A	Aqua
Color, connector B	Aqua
Construction Type	Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-24/UPC Female
Interface Feature, connector A	QSFP configuration
Interface, Connector B	MPO-12/UPC Female
Jacket Color	Aqua
Polarity	Method B Enhanced (ULL)
Total Fibers, quantity	24


## Dimensions

Cable Assembly Length Range (m)	3 – 999
---------------------------------	---------

# URX2CMPHF

Cable Assembly Length Range (ft) 10 – 999

## Ordering Tree

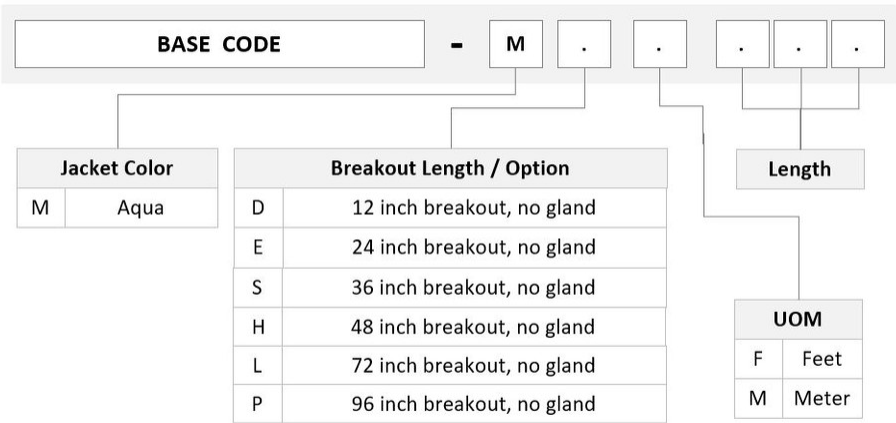

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0 ° | 4.40 lb @ 90 °

## Optical Specifications

**Fiber Mode** Multimode

**Fiber Type** OM4, LazrSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Indoor | Low Smoke Zero Halogen (LSZH)

## Regulatory Compliance/Certifications

### Agency

ISO 9001:2015

### Classification

Designed, manufactured and/or distributed under this quality management system



## Included Products

760161786 N-024-MP-5K-F36AQ/D – LazrSPEED® Low Smoke Zero Halogen Riser Light Duty MPO Patchcord Cable, 24 fiber

# URX2CMPHF

---

- 860617232 – MPO12, ULTRA LOW LOSS, FEMALE, OM5, LIME, 3mm
- 860634624 – LazrSPEED® Elite MPO Female 24 Fiber Connector, lime green