


URX2X2XHF

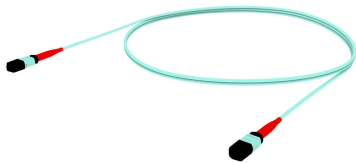

Ultra Low Loss (ULL) OM4 MPO/24 (Pinned) to MPO/24 (Pinned), 24-Fiber, Low Smoke Zero Halogen (LSZH)/Riser

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Fiber array cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Color, boot A	Red
Color, boot B	Red
Color, connector A	Aqua
Color, connector B	Aqua
Construction Type	Stranded
Fibers per Subunit, quantity	24
Furcation Color	Aqua
Interface, Connector A	MPO-24/UPC Male
Interface, Connector B	MPO-24/UPC Male
Jacket Color	Aqua
Polarity	Method B Enhanced (ULL)
Total Fibers, quantity	24


Dimensions

Cable Assembly Length Range (m)	1 – 305
---------------------------------	---------

URX2X2XHF

Cable Assembly Length Range (ft) 1 – 999

Ordering Tree

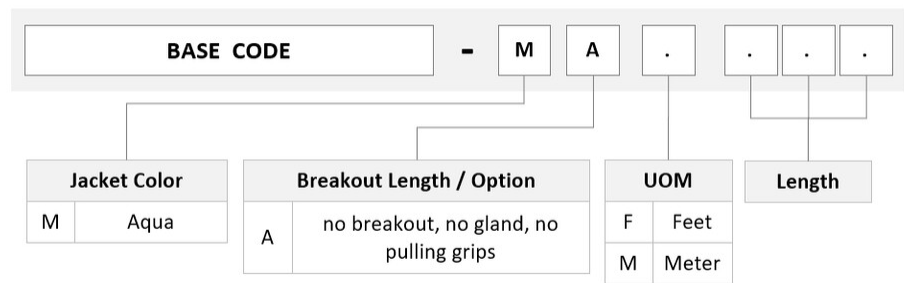

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Multimode

Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Indoor | Low Smoke Zero Halogen (LSZH)

Regulatory Compliance/Certifications

Agency

ISO 9001:2015

Classification

Designed, manufactured and/or distributed under this quality management system



Included Products

- | | | |
|---------------------|---|--|
| 760161786 | – | LazrSPEED® Low Smoke Zero Halogen Riser Light Duty MPO Patchcord Cable, 24 fiber |
| N-024-MP-5K-F36AQ/D | | |
| 860489152 | – | LazrSPEED® Elite MPO Male 24 Fiber Connector, aqua |