


URX2XLCHF

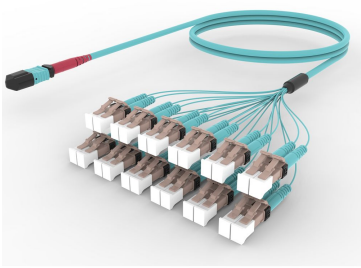

Ultra Low Loss OM4 MPO24 Pinned to LC/UPC 24-Fiber Low Smoke Zero Halogen Array Cord

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Fiber array cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Color, boot A	Red
Color, connector A	Aqua
Color, boot B	Aqua
Color, connector B	Beige
Construction Type	Stranded
Fibers per Subunit, quantity	24
Furcation Color	Aqua
Interface, Connector A	MPO-24/UPC Male
Interface, Connector B	LC/UPC
Jacket Color	Aqua
Polarity	Method B Enhanced (ULL)
Total Fibers, quantity	24


Dimensions

Breakout Length	12 in 24 in 36 in 48 in 60 in 72 in
-----------------	---

URX2XLCHF

Cable Assembly Length Range (m)	1 – 304
Cable Assembly Length Range (ft)	2 – 999

Ordering Tree

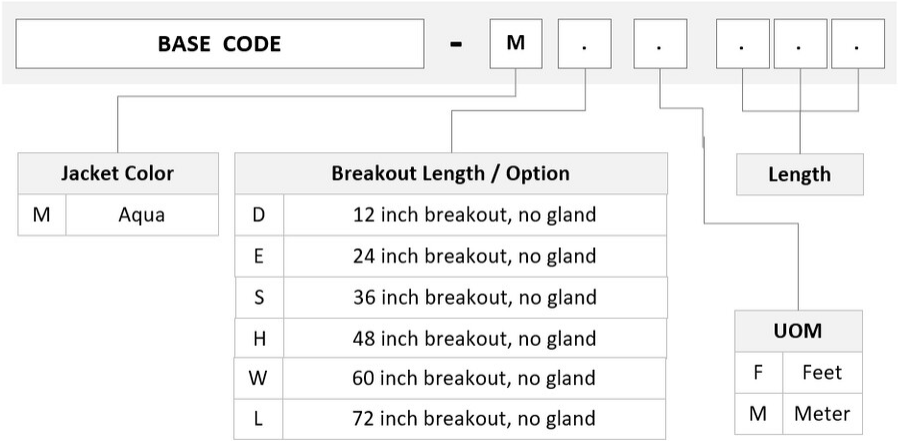

Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0 ° 4.40 lb @ 90 °
-----------------------------------	---------------------------------

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM4, LazrSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Indoor Low Smoke Zero Halogen (LSZH)

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system



Included Products

URX2XLCHF

760161786 N-024-MP-5K-F36AQ/D	-	Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser Light Duty for MPO Patchcords, 24 fiber, Multimode OM4, Gel-free, Feet jacket marking, Aqua jacket color, Dca flame rating
860637378	-	LazrSPEED® Elite LC Connector duplex for 1.6 mm Fiber, multimode
860637425	-	LC/UPC Connector, Multimode, Beige, Short Boot