

# AGXMXMXCL

## Base Product



Ultra Low Loss ULL LazrSPEED® 550 MPO(Pinned) to MPO(Pinned)  
Pre-terminated Trunk Cable, MPO12, 96-Fiber, Plenum, 12 fiber PmP 2.0  
mm Dca, Method A

## Product Classification

### Regional Availability

Asia | Australia/New Zealand | Europe | Latin America | Middle  
East/Africa | North America

### Portfolio

CommScope®

### Product Type

Fiber trunk cable assembly

### Ordering Note

For additional jacket colors, please contact a CommScope Sales  
Representative | For lengths greater than 999 ft (304 m), orders must be  
in meters | Minimum length may vary based on cable configuration

## General Specifications

### Color, boot A

Black

### Color, connector A

Black

### Color, boot B

Black

### Color, connector B

Black

### Construction Type

Stranded

### Furcation Color

Aqua

### Interface, Connector A

MPO-12/UPC Male

### Interface, Connector B

MPO-12/UPC Male

### Jacket Color

Aqua

### Polarity

Method A

### Fibers per Subunit, quantity

12

### Total Fibers, quantity

96

## Dimensions

### Breakout Length


33 in

# AGXMXMXCL

**Cable Assembly Length Range (m)** 3 – 999

**Cable Assembly Length Range (ft)** 10 – 999

## Ordering Tree

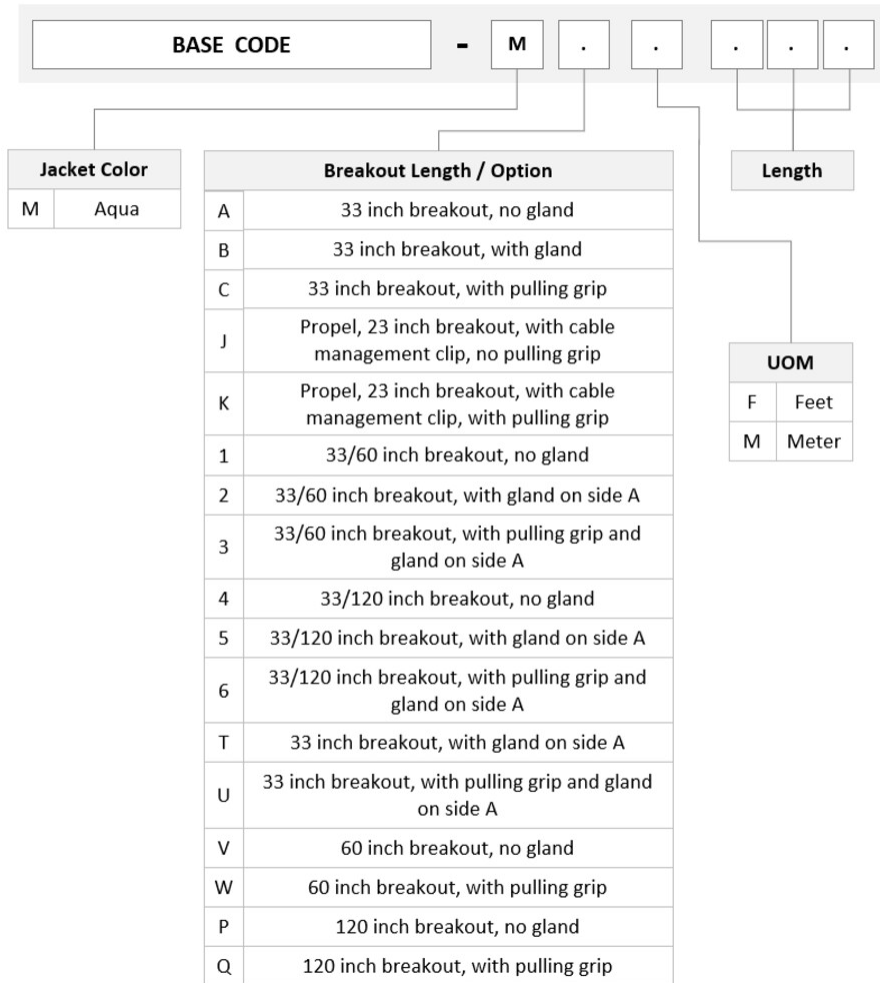

## Optical Specifications

**Fiber Mode** Multimode

**Fiber Type** OM4, LazrSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**EN50575 CPR Cable EuroClass Fire Performance** Dca

# AGXMXMXCL

Environmental Space

Indoor | Plenum

## Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



## Included Products

- 760242122  
P-096-MP-5K-F12AQ/20T
  - 860659006
- Fiber indoor cable, LazrSPEED® Plenum MPO Trunk, 96 fiber multi-unit with 12 fiber subunits, Multimode OM4, Gel-free, Feet jacket marking, Aqua jacket color
- MPO12, ULL, MALE, OM3/4, AQUA, 2MM