

# DFJ-2S320

---



HELIAX® Discrete, ruggedized, bend insensitive single mode 2 fiber cable, LC to HMFOC

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   EMEA   Latin America   North America
<b>Product Type</b>	Wireless Fiber Cable Assemblies
<b>Product Brand</b>	HELIAX®
<b>Product Series</b>	DFJ
<b>Ordering Note</b>	ANDREW® non-standard product

## General Specifications


<b>Construction Type</b>	Discrete fiber tail
<b>Interface, Connector A</b>	LC
<b>Interface Body Style, connector A</b>	Straight
<b>Interface, Connector B</b>	HMFOC
<b>Interface Feature, connector B</b>	Outdoor
<b>Interface Body Style, connector B</b>	Straight
<b>Jacket Color</b>	Black
<b>Total Fibers, quantity</b>	2

## Dimensions

<b>Cable Assembly Length Range (m)</b>	1 – 335
<b>Diameter Over Jacket</b>	5.4 mm   0.213 in

## Ordering Tree

# DFJ-2S320-10M

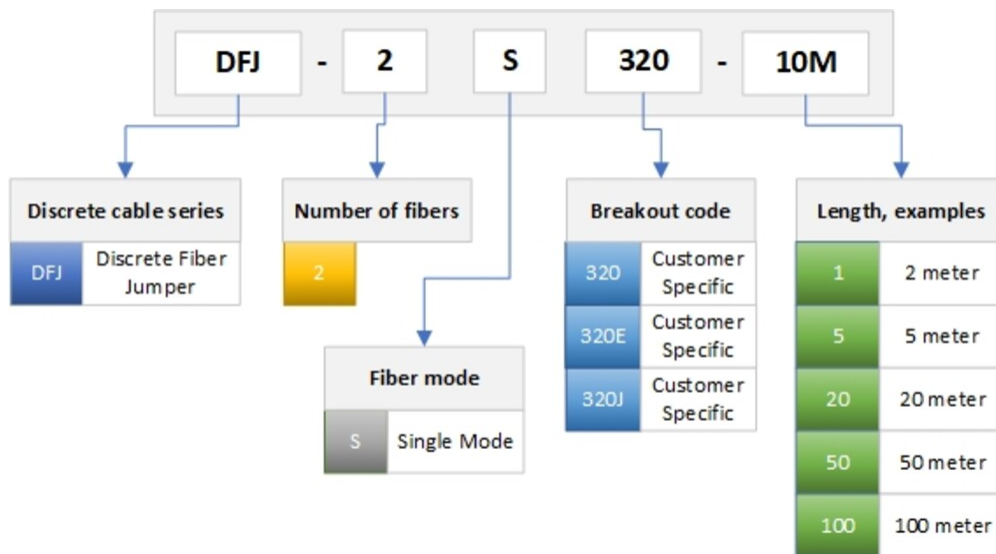

## Optical Specifications

<b>Fiber Mode</b>	Singlemode
<b>Fiber Type</b>	G.657.A2
<b>Insertion Loss, typical note</b>	Insertion loss is measured at 1310 and 1550 nm
<b>Insertion Loss, typical</b>	0.75

## Environmental Specifications

<b>Operating Temperature</b>	-40 °C to +70 °C (-40 °F to +158 °F)
<b>Environmental Space</b>	Outdoor

## Packaging and Weights

<b>Cable weight</b>	19 kg/km   12.767 lb/kft
---------------------	--------------------------

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



# DFJ-2S320

---

## \* Footnotes

**Insertion Loss, typical note** Insertion loss is measured at a room temp of +20°C (+68°F)