

DFJ-2S5A-EAS



HELIAX® Discrete, 2 single mode fiber, 5 mm LSZH armored cable. End 1: DLC for RRU. End 2: DLC for BBU. Includes installed weatherproofing shroud

Product Classification

| | |
|------------------------------|---|
| Regional Availability | Asia Australia/New Zealand EMEA Latin America North America |
| Product Type | Wireless Fiber Cable Assemblies |
| Product Brand | HELIAX® |
| Product Series | DFJ |
| Ordering Note | ANDREW® non-standard product |

General Specifications


| | |
|---------------------------------------|---------------------|
| Construction Type | Discrete fiber tail |
| Interface, Connector A | DLC |
| Interface Feature, connector A | Outdoor |
| Interface, Connector B | DLC |
| Jacket Color | Black |
| Total Fibers, quantity | 2 |

Dimensions

| | |
|--|-----------------|
| Cable Assembly Length Range (m) | 1 – 200 |
| Diameter Over Jacket | 5 mm 0.197 in |

Ordering Tree

DFJ-2S5A-EAS-10M

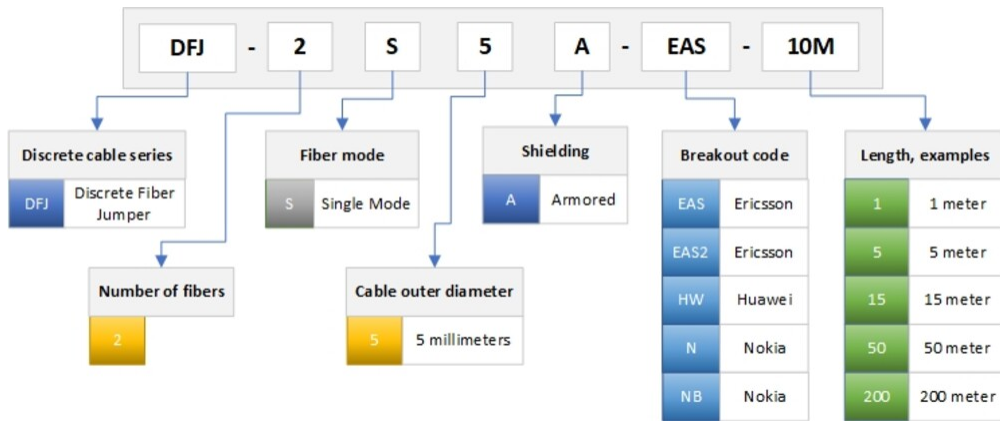

Material Specifications

Jacket Material Low Smoke Zero Halogen (LSZH)

Optical Specifications

Fiber Mode Singlemode

Fiber Type G.657.A2

Insertion Loss, typical note Insertion loss is measured at 1310 and 1550 nm

Insertion Loss, typical 0.5

Environmental Specifications

Operating Temperature -40 °C to +80 °C (-40 °F to +176 °F)

Environmental Space Outdoor

Packaging and Weights

Cable weight 35 kg/km | 23.519 lb/kft

Regulatory Compliance/Certifications

| | |
|---------------|--|
| Agency | Classification |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |

* Footnotes

Insertion Loss, typical note Insertion loss is measured at a room temp of +20°C (+68°F)