


2105092-3

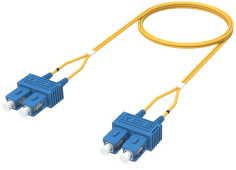

Fiber Optic Patch Cord, Duplex, OS2, SC/UPC to SC/UPC, LSZH & OFNR, yellow, 3 m

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Middle East/Africa
Portfolio	CommScope®
Product Type	Fiber patch cord, duplex
Product Series	210


General Specifications

Connector A, quantity	2
Color, boot A	Blue
Color, connector A	Blue
Connector B, quantity	2
Color, boot B	Blue
Color, connector B	Blue
Interface, Connector A	SC/UPC
Interface, Connector B	SC/UPC
Jacket Color	Yellow
Total Fibers, quantity	2

Dimensions

Cord Length	3 m 9.843 ft
Diameter Over Jacket	1.8 mm 0.071 in

 Ordering Tree



Examples of Lengths (meters)	
-7	7 meters
1- -0	10 meters
1- -5	15 meters
7- -0	70 meters
8- -0	80 meters
9- -y	Specific length

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	OS2
Insertion Loss, maximum, connector A	0.5 dB
Insertion Loss, maximum, connector B	0.5 dB
Return Loss, minimum, connector A	50 dB
Return Loss, minimum, connector B	50 dB

Environmental Specifications

Environmental Space	Low Smoke Zero Halogen (LSZH)
----------------------------	-------------------------------

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

