


1-2105028-0

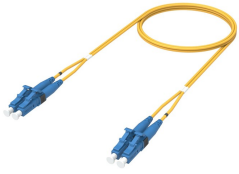

Fiber Optic Patch Cord, OS2, LC/LC duplex, 1.8 mm LSZH & OFNR, 10 m, yellow

Product Classification

Regional Availability	Asia Australia/New Zealand China India
Portfolio	CommScope®
Product Type	Fiber patch cord, duplex
Product Series	210

General Specifications


Connector A, quantity	2
Color, boot A	Blue
Color, connector A	Blue
Connector B, quantity	2
Color, boot B	Blue
Color, connector B	Blue
Interface, Connector A	LC/UPC
Interface, Connector B	LC/UPC
Jacket Color	Yellow
Polarity	Pairs, flipped
Total Fibers, quantity	2

Dimensions

Cord Length	10 m 32.808 ft
Diameter Over Jacket	1.8 mm 0.071 in

Ordering Tree

1-2105028-0

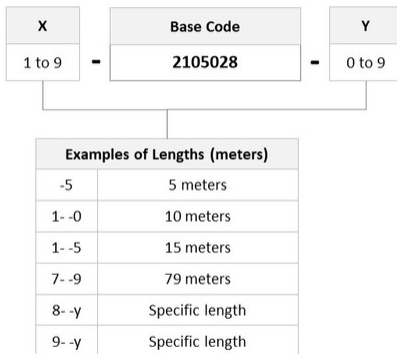

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	OS2
Insertion Loss, maximum, connector A	0.3 dB
Insertion Loss, maximum, connector B	0.3 dB
Return Loss, minimum, connector A	50 dB
Return Loss, minimum, connector B	50 dB

Environmental Specifications

Environmental Space	Dual Rated LSZH/Riser
Qualification Standards	IEC 60332-1 IEC 60332-3 IEC 60754 IEC 61034

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

1-2105028-0

