


CC0987-000 | OCP-E8-02MASEN-XX

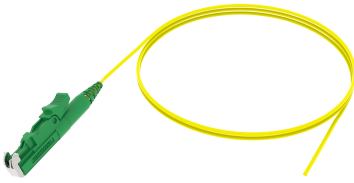

Fiber Optic Pigtail, Simplex, Singlemode, LSH/APC to Stub, 0.9 mm diameter, 2 m

OBSOLETE

This product was discontinued on: May 26, 2022

Product Classification

Regional Availability	EMEA
Product Type	Fiber pigtail, jacketed
Product Series	OCP

General Specifications

Connector A, quantity	1
Color, boot A	Green
Color, connector A	Green
Interface, Connector A	LSH/APC
Jacket Color	Yellow
Total Fibers, quantity	1

Dimensions

Cord Length	2 m 6.562 ft
--------------------	----------------

Ordering Tree

CC0987-000 | OCP-E8-02MASEN-XX



Connector/adapter type		
Standard C grade	Superior B grade	Type
S1	SF	SC/UPC
S2	SG	SC/APC 8°
S3	SH	SC/APC 9°
L1	LF	LC/UPC
L2	LG	LC/APC
-	EC	LSH/APC 8°

Cable type			Fiber type
ASEN	900 μm	Semi-tight jacket	A1
HSEN	900 μm	Semi-tight jacket	A2

Cable length	
02	2 meters

- Standard Configuration by default 900μm buffer
 buffer color : yellow
 250 μm color : natural or milky white

Optical Specifications

Fiber Mode Singlemode
Fiber Type G.657.A1, TeraSPEED®

Environmental Specifications

Environmental Space Low Smoke Zero Halogen (LSZH)

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency ISO 9001:2015
Classification Designed, manufactured and/or distributed under this quality management system

