

# LNXX-MNT

---

Side-By-Side Mounting Kit for 2.4- 4.5 inch (60 – 115 mm) OD round members.

- For LNX 65° models that are 8 feet, the LNXX-MNT-M is used for a center mount along with the LNXX-MNT

Side-By-Side Mounting Kit for 2.4"- 4.5" (60 – 115 mm) OD round members. This kit allows the mounting of two 65° type antennas which are 301 mm in width to be mounted side-by-side and provides customers the ability to build a quick and flexible antenna solution.

## OBSOLETE

This product was discontinued on: **March 27, 2020**

### Replaced By:

BSAMNT-SBS-1-2	Side-By-Side Mounting Kit to mount two antennas on a pipe with 2.375 - 4.5 inch (60 – 115 mm) diameter
----------------	--

## Product Classification

**Product Type** Side mounting kit

## General Specifications

**Application** Outdoor

**Color** Silver

## Dimensions

**Compatible Diameter, maximum** 115 mm | 4.528 in

**Compatible Diameter, minimum** 60 mm | 2.362 in

**Weight, net** 11.7 kg | 25.794 lb

## Material Specifications

**Material Type** Galvanized steel

## Packaging and Weights

**Included** Brackets | Hardware

**Packaging quantity** 1

**Weight, gross** 12.3 kg | 27.117 lb

## Regulatory Compliance/Certifications

# LNXX-MNT

---

## Agency

CHINA-ROHS  
ISO 9001:2015  
REACH-SVHC  
ROHS  
UK-ROHS

## Classification


Below maximum concentration value  
Designed, manufactured and/or distributed under this quality management system  
Compliant as per SVHC revision on [www.andrew.com/ProductCompliance](http://www.andrew.com/ProductCompliance)  
Compliant  
Compliant



## Included Products

- BSAMNT-3 – Wide Profile Antenna Downtilt Mounting Kit for 2.4 - 4.5 in (60 - 115 mm) OD round members. Kit contains one scissor top bracket set and one bottom bracket set.

# BSAMNT-3

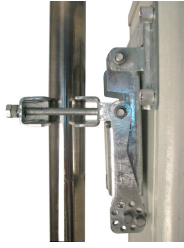

Wide Profile Antenna Downtilt Mounting Kit for 2.4 - 4.5 in (60 - 115 mm) OD round members. Kit contains one scissor top bracket set and one bottom bracket set.

## Product Classification

**Product Type** Downtilt mounting kit

## General Specifications

**Application** Outdoor

**Color** Silver

## Dimensions

**Compatible Diameter, maximum** 115 mm | 4.528 in

**Compatible Diameter, minimum** 60 mm | 2.362 in

**Weight, net** 6.2 kg | 13.669 lb

## Material Specifications

**Material Type** Galvanized steel

## Packaging and Weights

**Included** Brackets | Hardware

**Packaging quantity** 1

**Weight, gross** 6.4 kg | 14.11 lb

## Regulatory Compliance/Certifications

Agency	Classification
CE	Compliant with the relevant CE product directives
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.andrew.com/ProductCompliance">www.andrew.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant

# BSAMNT-3

---

