

# RCP-C4KBPUK09200

---



RapidFiber® Termination Panel, 288-Position 4RU, singlemode, LC/UPC to LC/UPC CMOD, 92m

## Product Classification

<b>Regional Availability</b>	Latin America   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber patch panel, with rapid cable
<b>Product Brand</b>	RapidFiber®
<b>Product Series</b>	RCP

## General Specifications

<b>Functionality</b>	Patching
<b>Body Style</b>	Symmetrical
<b>Cable Exit Location</b>	Rear, left side
<b>Cable Stub Type</b>	IFC, stranded
<b>Color</b>	Putty white
<b>Door Type, front</b>	Hinged   Slide latch   Transparent
<b>Growth Configuration</b>	Fully loaded
<b>Interface, front</b>	LC/UPC
<b>Interface, rear</b>	LC/UPC
<b>Patch Cord Entry Location</b>	Front, left side   Front, right side
<b>Rack Type</b>	EIA 19 in   EIA 23 in
<b>Rack Units</b>	4
<b>Shelf Movement</b>	Sliding
<b>Total Fibers, quantity</b>	288
<b>Total Ports, quantity</b>	288
<b>Transmission Standards</b>	IEC 60794-2   ISO/IEC 11801   TIA/EIA-568-B.3

## Dimensions


<b>Height</b>	177.8 mm   7 in
---------------	-----------------

# RCP-C4KBPUK09200

**Width** 482.6 mm | 19 in

**Depth** 381 mm | 15 in

## Ordering Tree

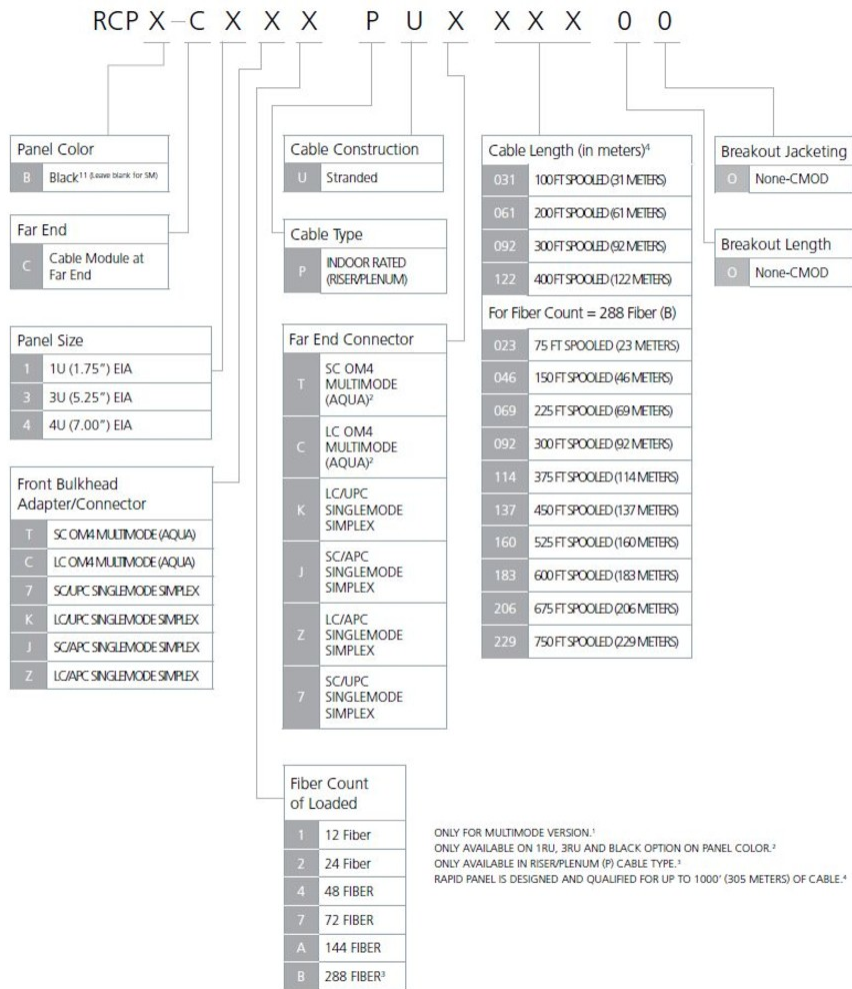

## Material Specifications

**Finish** Powder coated

**Material Type** Steel

## Optical Specifications

**Fiber Mode** Singlemode

**Fiber Type** G.652.D | G.657.A2/B2

# RCP-C4KBPUK09200

---

## Environmental Specifications

<b>Operating Temperature</b>	-5 °C to +55 °C (+23 °F to +131 °F)
<b>Storage Temperature</b>	-40 °C to +70 °C (-40 °F to +158 °F)
<b>Relative Humidity</b>	5%–85%, non-condensing
<b>Qualification Standards</b>	NEBS Level 3   Telcordia GR-1435   Telcordia GR-326   Telcordia GR-409   UL 1863

## Packaging and Weights

<b>Packaging quantity</b>	1
---------------------------	---

## Included Products

760245201 P-024-MP-8V-F30YL	–	Fiber indoor cable, Plenum for MPO Light Duty Patchcords, 24 fiber, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color
--------------------------------	---	--