

TFAM18/21P-14



ION®-B Series Medium Power Remote Unit for GSM 1800 and UMTS

OBSOLETE

Product Classification


 
Product Type Remote unit
Product Brand ION®-B

General Specifications

Note Detailed Product Specifications are available. Please contact your local CommScope representative.
Power Class Medium

Dimension Drawing

TFAM18/21P-14

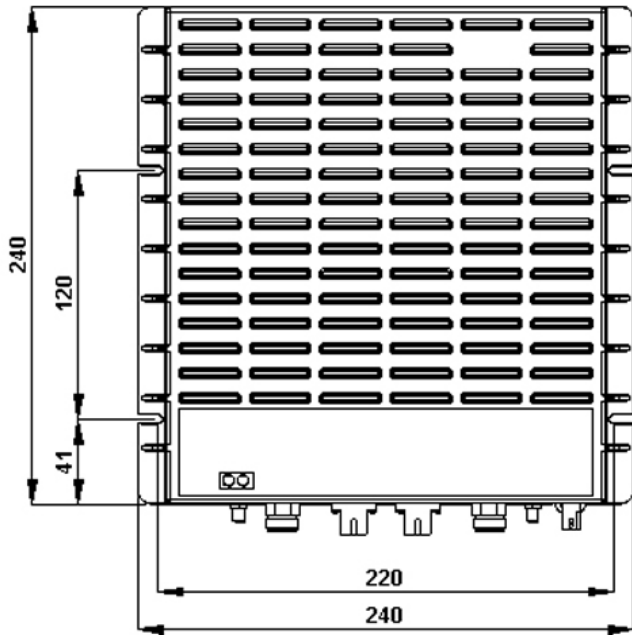

Electrical Specifications

Impedance	50 ohm
License Band	GSM 1800 UMTS
Voltage Range	85 to 265 Vac

Electrical Specifications, Rx (Uplink)

Operating Frequency Band	1710 – 1785 MHz (GSM 1800) 1920 – 1980 MHz (UMTS)
---------------------------------	---

Electrical Specifications, Tx (Downlink)

Operating Frequency Band	1805 – 1880 MHz (DCS 1800) 2110 – 2170 MHz (UMTS)
---------------------------------	---

Regulatory Compliance/Certifications

TFAM18/21P-14

Agency

CHINA-ROHS

ISO 9001:2015

REACH-SVHC

ROHS

UK-ROHS



Classification

Below maximum concentration value

Designed, manufactured and/or distributed under this quality management system

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

Compliant

Compliant/Exempted

Included Products

TPSN1/32-80 – Power Supply Adapter ION®-B Series Remote Units, 80 W