

TFBM7/70-1



ION®-B Series Extension Unit for Cellular 700 and LMR 700

OBSOLETE

This product was discontinued on: August 24, 2016

Product Classification


Product Type	Extension unit
Product Brand	ION®-B

General Specifications

Note	Detailed Product Specifications are available. Please contact your local CommScope representative.
Power Type	Medium

Dimension Drawing

TFBM7/70-1

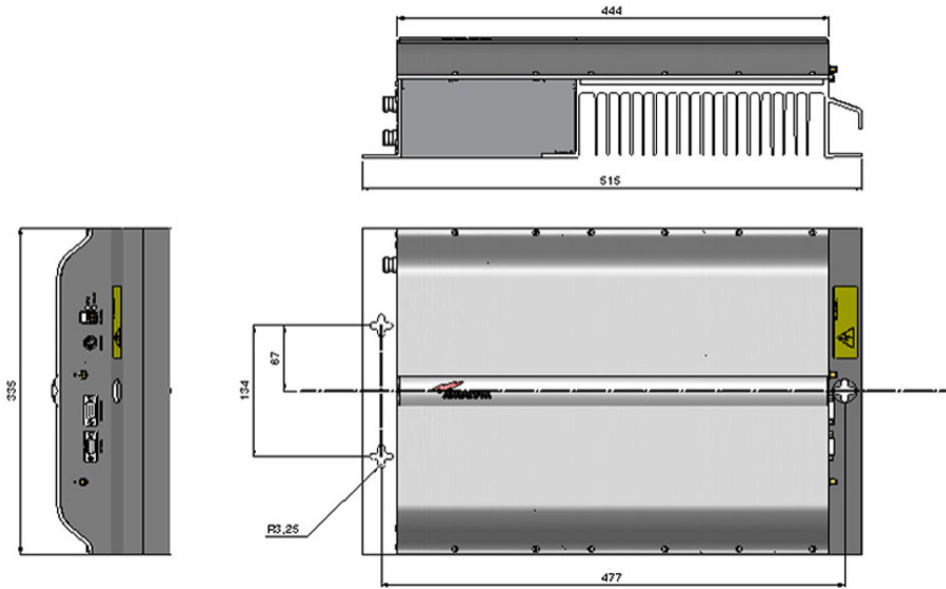

Electrical Specifications


Impedance	50 ohm
License Band	Cellular 700 LMR 700
Voltage Range	-60 to -36 Vdc

Electrical Specifications, Tx (Downlink)

Operating Frequency Band	728 – 757 MHz (Cellular 700) 758 – 776 MHz (LMR 700)
---------------------------------	--

Cabling Drawing

TFBM7/70-1

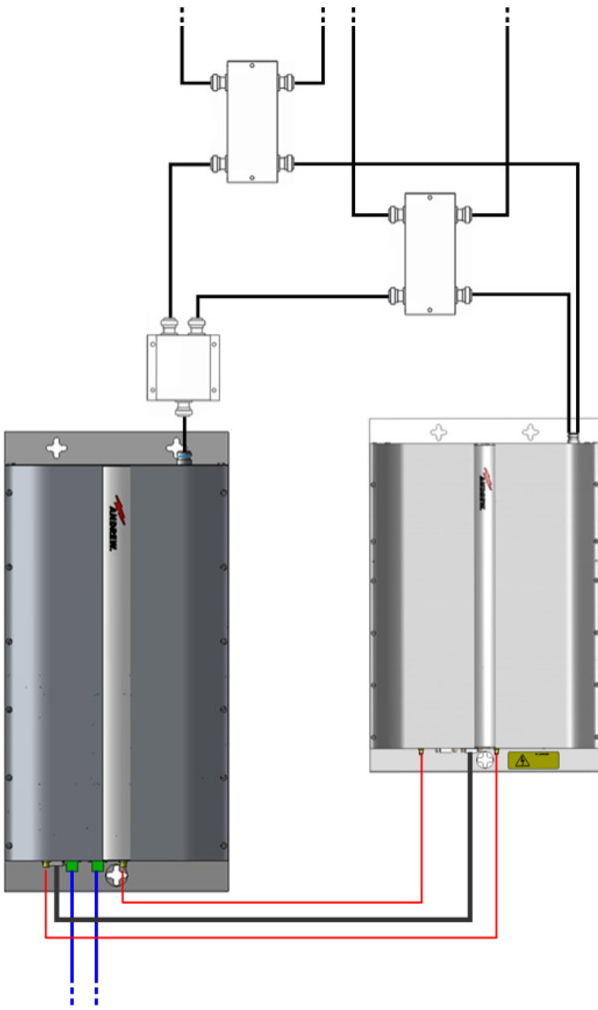

Regulatory Compliance/Certifications

Agency

CHINA-ROHS

ISO 9001:2015

ROHS

Classification

Above maximum concentration value

Designed, manufactured and/or distributed under this quality management system

Compliant/Exempted



Included Products

- TPSN1/28-80 – Power Supply Adapter ION®-B Series Remote Units, 80 W
- TPSN3/28-80 – Power Supply Adapter ION®-B Series Remote Units, 80 W

TPSN1/28-80

Power Supply Adapter ION®-B Series Remote Units, 80 W



Product Classification

Product Type

Power adapters

Product Brand


ION®-B

General Specifications

Note

Detailed Product Specifications are available. Please contact your local CommScope representative.

Dimension Drawing

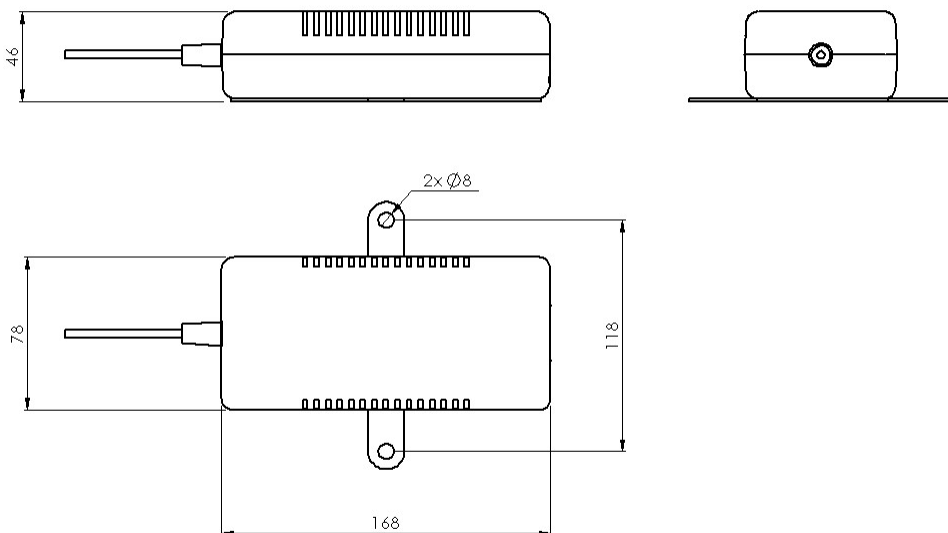

TPSN1/28-80

Electrical Specifications

Output Power, maximum

80 W

Regulatory Compliance/Certifications

Agency

ISO 9001:2015

Classification

Designed, manufactured and/or distributed under this quality management system



TPSN3/28-80

Power Supply Adapter ION®-B Series Remote Units, 80 W




Product Classification

Product Type	Power adapters
Product Brand	ION®-B

General Specifications

Note	Detailed Product Specifications are available. Please contact your local CommScope representative.
-------------	--

Dimension Drawing

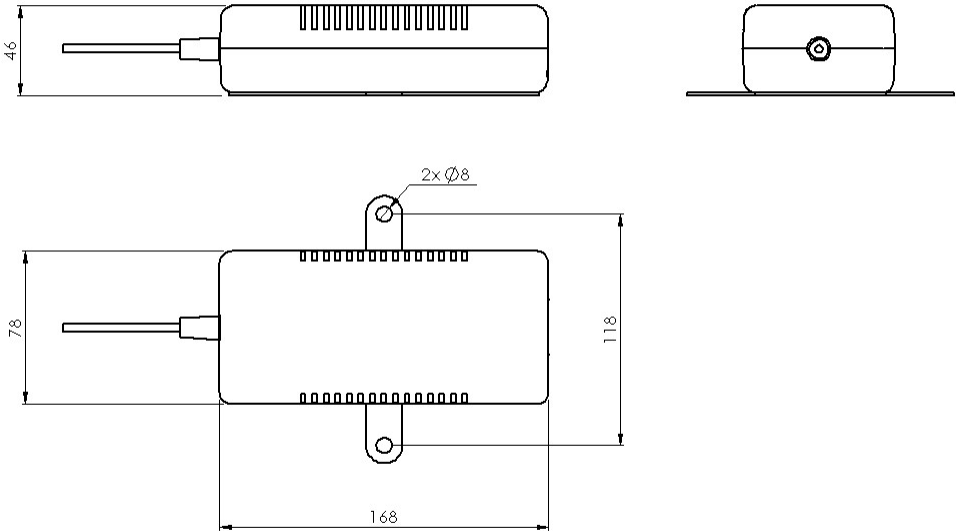

TPSN3/28-80

Electrical Specifications

Output Power, maximum

80 W

Regulatory Compliance/Certifications

Agency

ISO 9001:2015

Classification

Designed, manufactured and/or distributed under this quality management system

