


760249049 | G2iP-SP-24LC

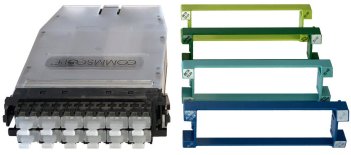

G2 Splice Cassette, 24LC, intelligent-ready, no pigtails

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	SYSTIMAX®
Product Type	Fiber cassette
Product Series	G2

General Specifications

Color, front	Aqua Blue Green Lime green
Intelligence Type	iPatch® ready
Interface, front	LC/UPC
Interface Feature, front	Dust caps
Interface, rear	No pigtail
Shuttered	No
Total Fibers, quantity	24

Dimensions

Height	26.416 mm 1.04 in
Width	96.52 mm 3.8 in
Depth	165.354 mm 6.51 in

Environmental Specifications

Qualification Standards	IEC 61753-1 TIA-568.3-D
Safety Standard	UL

Packaging and Weights

Included	SMOUV holder SMOUV splice protection
Packaging quantity	1

Weight, net

0.107 kg | 0.235 lb

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Below maximum concentration value

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant

