


FGS-MH9E-F-VS

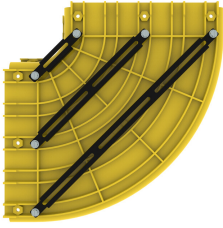

FiberGuide® Variable Support Kit for 4x12in 90° Horizontal Elbow

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Support mounting kit
Product Brand	FiberGuide®
Product Series	FGS

General Specifications

Color	Yellow
Orientation	Horizontal
Section Type	Elbow section

Dimensions

System Dimensions	102 mm x 305 mm (4 in x 12 in)
--------------------------	--------------------------------

Ordering Tree

9		10
FGS	B	MH9E - A

Section Color

9	empty	yellow
	B	black

* Support brackets only come in black

Section Size

10	A	4 x 4 in
	B	4 x 6 in
	F	4 x 12 in
	F-VS	4 x 12 in , variable support bracket
	G	2 x 6 in
	M	4 x 18 in

Material Specifications

FGS-MH9E-F-VS

Material Type Engineering Thermoplastic

Environmental Specifications

Flammability Rating CSA S143 | UL 2024 | UL 94 V-0

Halogen Characteristics Blue Angel | TCO '99 | WEEE

Safety Standard CSA | UL

Packaging and Weights

Weight, net 1.134 kg | 2.5 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

