


FGS-MHXP-F-VS

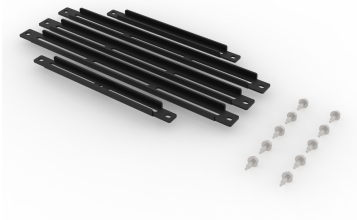

FiberGuide® Variable Support Kit for 4x12in Cross Section

Product Classification

| | |
|------------------------------|---|
| Regional Availability | Asia Australia/New Zealand EMEA Latin America North America |
| Portfolio | CommScope® |
| Product Type | Support mounting kit |
| Product Brand | FiberGuide® |
| Product Series | FGS |

General Specifications

| | |
|---------------------|---------------|
| Color | Black |
| Orientation | Horizontal |
| Section Type | Cross section |

Dimensions

| | |
|--------------------------|--------------------------------|
| System Dimensions | 102 mm x 305 mm (4 in x 12 in) |
|--------------------------|--------------------------------|

Ordering Tree

FGS-MHXP-F-VS



Section Color

| | | |
|---|-------|--------|
| 9 | empty | yellow |
| | B | black |

Section Size

| | | |
|------|-------------------------------------|---|
| 10 | A | 4 x 4 in |
| | B | 4 x 6 in |
| | B/F | 4 x 12 in, with two 4 x 6 in exits |
| | B/F-VS | 4 x 12 in, with two 4 x 6 in exits, variable support bracket |
| | C | 2 x 2 in |
| | F | 4 x 12 in |
| | F/H | 4 x 24 in, with two 4 x 12 in exits |
| | F/H-VS | 4 x 24 in, with two 4 x 12 in exits, variable support bracket |
| | F/VS | 4 x 12 in, variable support bracket |
| | G | 2 x 6 in |
| | H | 4 x 24 in |
| H-VS | 4 x 24 in, variable support bracket | |

* Support brackets only come in black

Material Specifications

Material Type Engineering Thermoplastic

Environmental Specifications

Flammability Rating CSA S143 | UL 2024 | UL 94 V-0

Halogen Characteristics Blue Angel | TCO '99 | WEEE

Safety Standard CSA | UL

Packaging and Weights

Weight, net 1.593 kg | 3.512 lb

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Below maximum concentration value

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant

