


FGS-MSHS-D

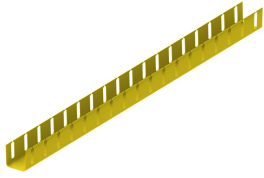

FiberGuide® Vertical Straight Section with 4in Slot Spacing, 4x4in, Yellow

Product Classification

| | |
|------------------------------|---|
| Regional Availability | Asia Australia/New Zealand EMEA Latin America North America |
| Portfolio | CommScope® |
| Product Type | Slotted vertical |
| Product Brand | FiberGuide® |
| Product Series | FGS |

General Specifications

| | |
|------------------------|------------------|
| Product Feature | Slotted |
| Color | Yellow |
| Orientation | Vertical |
| Section Type | Straight section |

Dimensions

| | |
|--------------------------|-------------------------------|
| Height | 101.6 mm 4 in |
| Width | 101.6 mm 4 in |
| Length | 1829 mm 72.008 in |
| System Dimensions | 102 mm x 102 mm (4 in x 4 in) |

Material Specifications

| | |
|----------------------|---------------------------|
| Material Type | Engineering Thermoplastic |
|----------------------|---------------------------|

Environmental Specifications

| | |
|--------------------------------|--------------------------------|
| Flammability Rating | CSA S143 UL 2024 UL 94 V-0 |
| Halogen Characteristics | Blue Angel TCO '99 WEEE |
| Safety Standard | CSA UL |

Packaging and Weights

FGS-MSHS-D

Weight, net

1.965 kg | 4.332 lb

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Below maximum concentration value

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant

